




**LXEN**

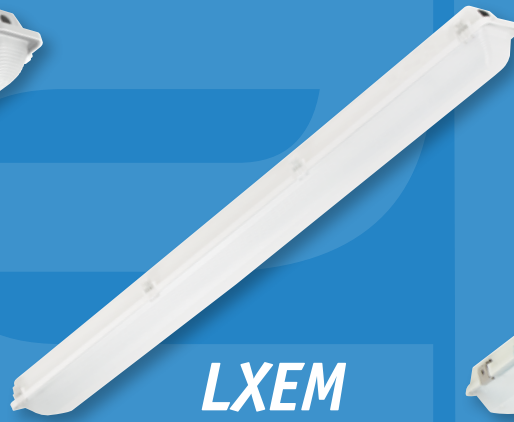

**LXEM**



**LXEW**

# XE Family LED Enclosed & Gasketed Luminaires

*A full family of LED linear enclosed and gasketed luminaires for rough service applications*



DLC® (DesignLights Consortium)  
Qualified, with some Premium Qualified configurations - see [www.designlights.org](http://www.designlights.org)

	LXEN	LXEM	LXEW
	Narrow 4' housing fits easily into confined spaces	Mid-size and mainstream, offering the widest selection of options	An enclosed high bay/low bay for demanding areas
<b>Width</b>	4"	6 <sup>7</sup> / <sub>8</sub> "	15"
<b>Available Lengths</b>	4'	2', 4', 8'	4'
<b>IP65</b>	✓	✓	✓
<b>IP66 with standard latches</b>	✓	✓	✓
<b>IP67</b>	✓	✓	✓
<b>Wet Label</b>	✓	✓	✓
<b>F1 Weatherability (UV resistance)</b>	✓	✓	✓
<b>UL Sanitation to NSF Standards</b>	✓	✓	✓
<b>Lumen Packages</b>	2,000 – 4,300	3,150– 22,473	11,079 – 38,228
<b>Fluorescent Replacement</b>	1-T8, 2-T8, 1-T5HO	2-T8, 3-T8, 4-T8, 2-T5HO, 4-T5HO	4T-8, 6-T8, 8-T8, 4-T5HO, 6-T5HO, 8-T5HO

**LXEN** **4** - **RFA** - **U**

MODEL	SIZE	COLOR TEMP	SHIELDING	DRIVER	VOLTAGE	OPTIONS
<b>LXEN</b> LED Narrow Enclosed and Gasketed	4 4'	30 3000K 35 3500K 40 4000K 50 5000K	<b>RFA</b> Ribbed Frosted Acrylic <sup>1</sup>	<b>E</b> Fixed Output <b>ED</b> 0-10V Dimming	<b>U</b> 120V- 277V	<b>GLR</b> Fast Blow Fuse <b>DTS</b> Dimming Bypass Module <sup>2</sup> <b>SSL</b> Stainless Steel Tamper Resistant Ready Latches <b>TP</b> Tamper Proof Latches <b>F3C8W</b> 3 Wire 8' Wet Cord <b>F3C15W</b> 3 Wire 15' Wet Cord <b>SWH</b> Single Wet Hub 1/2" NPT Hub <b>DWH</b> Dual Wet Hub 1/2" NPT Hub

**LUMEN OUTPUT**  
**XW** Extra Low Watt  
**LW** Low Watt

LXEN PRODUCT AVAILABILITY			
Length	XW	LW	Efficacy Up To
4'	2,000 - 2,200	3,800 - 4,300	122

Nominal lumen range represents 3000K through 5000K. Lumens vary according to color temperatures and other factors. See specific photometric test(s).

<sup>1</sup> Standard impact resistant equivalent to 100% DR  
<sup>2</sup> For emergency circuit control loads including sensors and wireless systems listed to UL924. Only available with 0-10V driver

**LXEM** - - - - -

MODEL	SIZE	COLOR TEMP	SHIELDING	DRIVER	VOLTAGE	OPTIONS
<b>LXEM</b> LED Enclosed & Gasketed	2 2' <sup>1,2,3,4</sup> 4 4' 8 8'	30 3000K 35 3500K 40 4000K 50 5000K	<b>RFA</b> Ribbed Frosted Acrylic <b>RA</b> Ribbed Clear Acrylic <sup>5</sup> <b>DFA</b> Deep Frosted Acrylic <b>DCA</b> Deep Clear Acrylic <sup>5</sup> <b>RFP</b> Ribbed Frosted Polycarbonate <sup>6</sup> <b>RP</b> Ribbed Clear Polycarbonate <sup>5,6</sup>	<b>E</b> Fixed Output <b>ESD</b> Step Dimming <sup>7</sup> <b>ED</b> 0-10V Dimming <b>ED1</b> 0-10V 1% Dimming <sup>7</sup>	<b>U</b> 120V- 277V <b>347</b> 347V	<b>ELL14</b> Emergency Battery Pack Installed, 1400 Lumens <sup>3,7,8</sup> <b>GLR</b> Fast Blow Fuse <b>DTS</b> Dimming Bypass Module <sup>3,8,9</sup> <b>OCM</b> Microwave Occupancy Sensor <sup>8,13</sup> <b>SSL</b> Stainless Steel Tamper Resistant Ready Latches <b>TP</b> Tamper Proof Latches <b>F3C8W</b> 3 Wire 8' Wet Cord <b>F3C15W</b> 3 Wire 15' Wet Cord <b>F4C8W</b> 4 Wire 8' Wet Cord <b>F4C15W</b> 4 Wire 15' Wet Cord <b>F5C8W</b> 5 Wire 8' Wet Cord <b>F5C15W</b> 5 Wire 15' Wet Cord <b>F6C6W</b> 6 Wire 6' Wet Cord <b>SWH</b> Single Wet Hub 1/2" NPT Hub <b>DWH</b> Dual Wet Hub 1/2" NPT Hub <b>ZRE</b> ControlScope <sup>®</sup> compatible <sup>8,10</sup>

**ACCESSORIES (ORDER SEPARATELY)**  
**XEDPM** Dual Pendant Brackets (pendant by others)<sup>11</sup>  
**XEHC** Chain Hanger Kit (Includes 14" Chain)  
**XE45MB** 45° Mounting Bracket<sup>12</sup>  
**XE45MBSS** 45° Stainless Steel Mounting Bracket<sup>12</sup>

**LUMEN OUTPUT**  
**VW** Very Low Watt  
**LW** Low Watt  
**ML** Medium Lumen  
**HL** High Lumen  
**VL** Very High Lumen  
**XL** Xtra High Lumen<sup>2</sup>

**SENSOR KITS (Order Separately)**  
All sensor kits include On/Off Occupancy & Daylight. Daylight activation requires setting of dip-switches on site.

Catalog #	# Relays	Lens Type	Voltage	Wet Label
120V/ 277V OS1360WLK	1	360°	120/277	Yes
OS2360WLK	2	360°	120/277	Yes
OS1AWLK	1	Aisle	120/277	Yes
OS2AWLK	2	Aisle	120/277	Yes

LXEM PRODUCT AVAILABILITY						
Length	VW	LW	ML	HL	VL	XL
2'	2,145 - 2,708	2,738 - 3,529	3,862 - 4,921	4,254 - 5,416	-	-
4'	2,802 - 3,433	3,726 - 4,922	4,533 - 5,646	5,449 - 6,763	7,086 - 8,415	9,059 - 11,237
8'	6,078 - 6,866	8,095 - 9,276	9,844 - 11,293	11,851 - 13,525	14,747 - 16,830	19,558 - 22,473

Lumens vary according to color temperatures and other factors. See specific photometric test(s).

<sup>1</sup> VL and XL not available in 2' size  
<sup>2</sup> Not available with battery pack or DTS  
<sup>3</sup> Not available with XL lumen package  
<sup>4</sup> Not available with VL lumen package  
<sup>5</sup> Clear lenses (RA, DCA and RP) may cause noticeable light patterns on lit surfaces. See ies files for exact distribution  
<sup>6</sup> 2' and 4' only. 8' not available  
<sup>7</sup> See table for availability  
<sup>8</sup> Not available in 347V  
<sup>9</sup> For emergency circuit control loads including sensors and wireless systems listed to UL924. Only available with 0-10V drivers  
<sup>10</sup> Registered trademark of Daintree Networks, used by permission  
<sup>11</sup> Requires 3/8" OD threaded rod by others  
<sup>12</sup> 2 required for 8' fixture  
<sup>13</sup> OCM option uses Wattstopper FM-105

**LXEW** **4** - - - - -

MODEL	SIZE	LUMEN OUTPUT	LENS	DRIVER	DISTRIBUTION	VOLTAGE	OPTIONS
<b>LXEW</b> Industrial Enclosed & Gasketed LED High Bay	4 4'	<b>L</b> Low Watt <b>M</b> Medium Lumen <b>MH</b> Medium High Lumen <b>H</b> High Lumen <b>HV</b> High Very High Lumen <b>V</b> Very High Lumen <b>X</b> Extra High Lumen	<b>FA</b> Frost Impact Resistant Acrylic (std.) <b>CA</b> Clear Impact Resistant Acrylic <b>CP</b> Clear UV Stabilized Polycarbonate	<b>E</b> Fixed Output <b>ED</b> 0-10V Dimming	<b>N</b> Narrow Distribution <b>W</b> Wide Distribution	<b>U</b> 120V- 277V <b>347</b> 347V <sup>1</sup> <b>480</b> 480V <sup>1</sup>	<b>ELL14</b> Emergency Battery Pack Installed, 1400 Lumens <sup>2,3</sup> <b>GLR</b> Fast Blow Fuse <sup>2</sup> <b>OCM</b> Microwave Occupancy Sensor <b>DTS</b> Dimming Bypass Module <sup>2,3,4</sup> <b>SSL</b> Stainless Steel Tamper Resistant Ready Latches <b>TP</b> Tamper Proof Latches <b>F3C8W</b> 3 Wire 8' Wet Cord <b>F3C15W</b> 3 Wire 15' Wet Cord <b>F4C8W</b> 4 Wire 8' Wet Cord <b>F4C15W</b> 4 Wire 15' Wet Cord <b>F5C8W</b> 5 Wire 8' Wet Cord <b>F5C15W</b> 5 Wire 15' Wet Cord <b>F6C6W</b> 6 Wire 6' Wet Cord <b>SWH</b> Single Wet Hub 1/2" NPT Hub <b>DWH</b> Dual Wet Hub 1/2" NPT Hub

**ACCESSORIES (ORDER SEPARATELY)**  
**LHVQM5** Aircraft Cable, 5' (Pair)  
**LHVQM10** Aircraft Cable, 10' (Pair)  
**XEWMHSS** Mounting Strap Hardware Kit, Stainless Steel  
**XEWRBZN** Rigid Surface Mounting Bracket Kit, Zinc Plate  
**XEWRBSS** Rigid Surface Mounting Bracket Kit, Stainless Steel  
**XEWFSS** Surface Mounting Bracket Kit, Stainless Steel

LXEW PRODUCT AVAILABILITY							
Length	L	M	MH	H	HV	V	X
4'	11,079 - 12,495	15,349 - 16,539	16,580 - 18,689	20,714 - 22,321	23,805 - 25,651	29,040 - 32,557	35,357 - 38,099

Lumens vary according to color temperatures and other factors. See specific photometric test(s).

<sup>1</sup> Not available with V and X packages  
<sup>2</sup> Not available with 347V/480V  
<sup>3</sup> Not available with HV, V, X lumen packages  
<sup>4</sup> For emergency circuit control loads including sensors and wireless systems listed to UL924. Only available with 0-10V drivers