

Watertight Devices
Accessories
Portable Outlet Box

HUBBELL

Features

- Fully thermoplastic elastomer housing exceeds UL crush requirements
- Wiring room large enough to accommodate the broadest range of device requirements
- Brass inserts for maximum strength

Ordering Information

Description	Device Color	UPC	Catalog Number
Portable outlet box with (2) duplex plates	Yellow	783585433387	HBL3000

Listings



Listed to UL514C
UL Type 3R
Meets NEMA WD-1, WD-6 and ANSI standards
UL listed for pendant or feed through mounting, File E92074

Specifications

Box Enclosure	Thermoplastic Elastomer
Gotcha Ring	Polypropylene
Strain Relief Nut	Nylon
Grommet	Thermoplastic Elastomer
Locknut	Steel, Zinc Plate
Threaded Inserts	Brass

Performance

Environmental	
Flammability	UL94 V-0
Moisture Resistance	UL Type 3R
Operating temperatures	-40°C (without impact) to +60°C continuous
UV Resistance	All exposed materials are UV stabilized
Mechanical	
Cord Accomodation	.38" - .63"

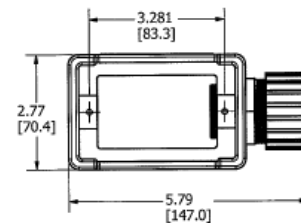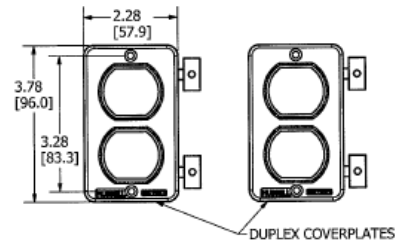

Complementary Products

UL Type 1 duplex outlet box cover	HBL3051
UL Type 3R duplex outlet box cover	HBL3056
UL Type 1 outlet box cover with 1.39" diameter single receptacle	HBL3052
UL Type 3R outlet box cover with 1.39" diameter single receptacle	HBL3057
UL Type 1 outlet box cover with 1.57" diameter single receptacle	HBL3055
UL Type 3R outlet box cover with 1.57" diameter single receptacle	HBL3058
UL Type 1 outlet box cover for GFCI receptacle	HBL3060
UL Type 3 outlet box cover for GFCI receptacle	HBL3061
Blank outlet box coverplate	HBL3054

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

Online Resources

eCatalog

