


DEWALT
GUARANTEED TOUGH.

D25263K
1-1/8" SDS Rotary Hammer

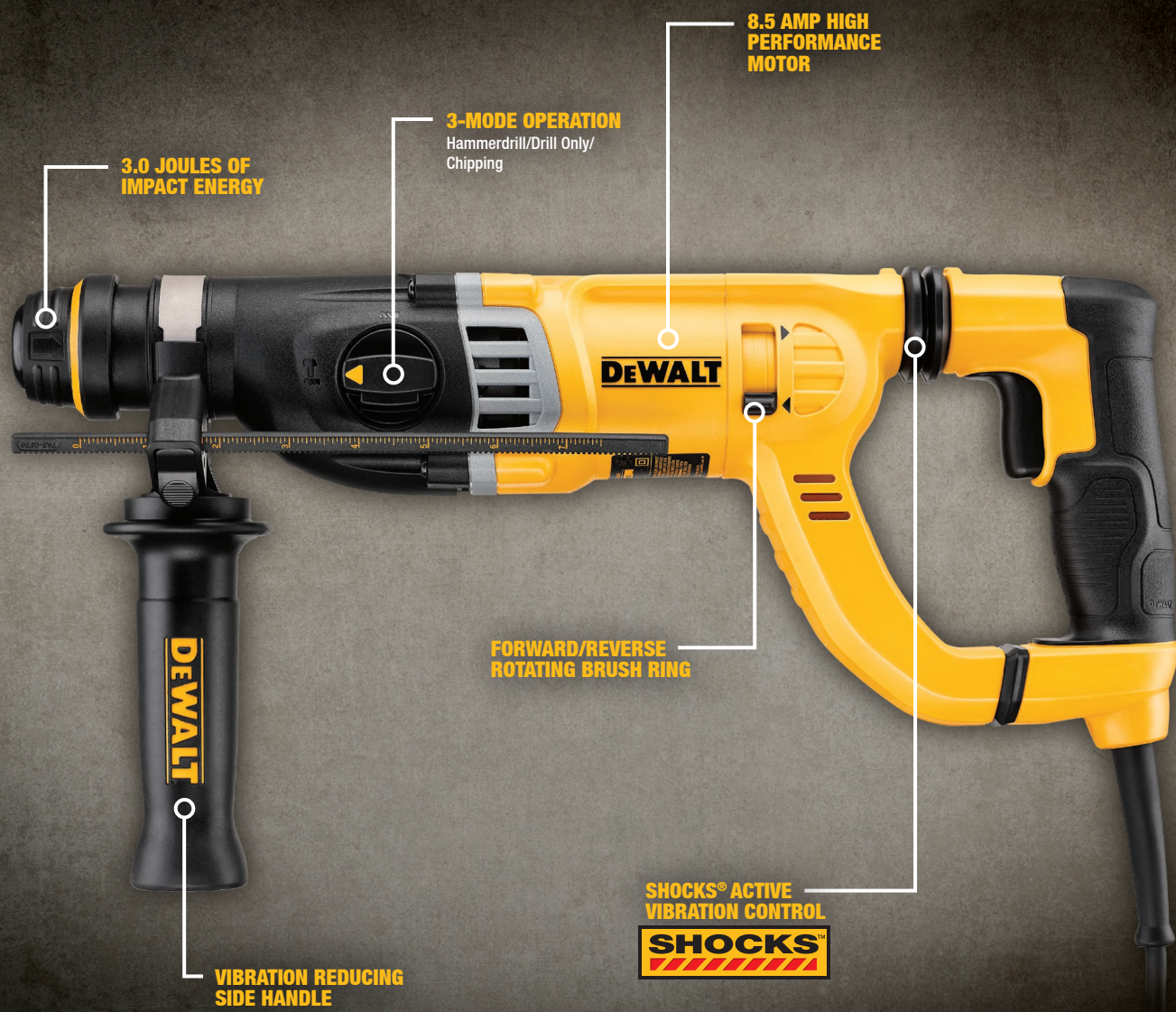

**15% Faster
Drilling Speed***



ICD25263KSS

4/15

*On average compared to Bosch Bulldog Extreme Max (RH228VC) when drilling 5/8" x 3" holes

DEWALT®



1" Pistol Grip SDS Hammer



7/8" SDS Hammer



1" SDS Hammer



1-1/8" SDS Hammer

Specifications	D25133K	D25260K	D25262K	25263K
Amps	8.0	7.0	8.0	8.5
Impact Energy**	2.6 J	2.6 J	2.8 J	3.0 J
Vibration Control	No	No	SHOCKS™	SHOCKS™
No Load Speed	0-1500	0-1500	0-1500	0-1450
Beats/Min	0-5500	0-5500	0-5540	0-5350
Vibration Measurement	15.4 m/s ²	15.2 m/s ²	9.6 m/s ²	9.8 m/s ²
Tool Weight	5.7 lbs.	5.9 lbs.	6.6 lbs.	6.8 lbs.
Service Warranty	1 Year	1 Year	2 Year	2 Year



Dealer Stamp

1-800-4 DEWALT®

www.DEWALT.com

Copyright ©2015 DEWALT. The following are examples of trademarks for one or more DEWALT power tools and accessories: The yellow and black color scheme; the "D"-shaped air intake grill; the array of pyramids on the handgrip; the kit box configuration; and the array of lozenge-shaped humps on the surface of the tool.

**According to EPTA-Procedure 05/2009