

# Flexible-tube luminaire

## ABLTL 1

112385M10

# Waldmann **W**

ENGINEER OF LIGHT.




**light source**  
**work equipment**  
**connected load**  
**power consumption**  
**luminous flux**  
**luminous efficiency**  
**light type/color**  
**color temperature**  
**color rendering index**  
**light distribution**  
**system of protection**  
**class of protection**  
**operation**  
**housing**  
**cover**  
**mains lead**  
**fastening**  
**color temperature**  
**special features**

LED  
without  
110-230 V; 50/60 Hz  
approx. 3 W  
approx. 180 lm  
approx. 60 lm/W  
daylight  
approx. 6,500 K  
CRI > 75  
narrow-beam; direct  
IP 67  
III  
external  
aluminum; anodized; jet black  
borosilicate  
built-in plug; 5.00 m (197")  
table clamp (accessory); wall bracket (accessory); screw-down flange  
spot with 6° angle of reflected beam

illuminance

E<sub>min</sub>: 69 lx  
E<sub>m</sub>: 1219 lx  
E<sub>max</sub>: 8966 lx

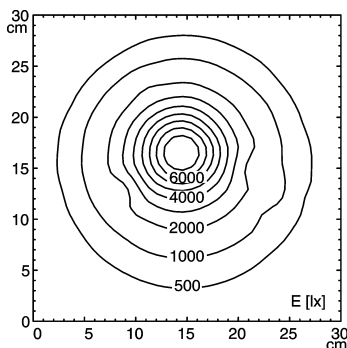

luminous intensity

