

Flexible-tube luminaire ABLTL 1

112385M20

Waldmann **W**


ENGINEER OF LIGHT.



light source	LED
work equipment	without
connected load	20/28 V; DC
power consumption	approx. 3 W
luminous flux	approx. 180 lm
luminous efficiency	approx. 60 lm/W
light type/color	daylight
color temperature	approx. 6,500 K
color rendering index	CRI > 75
light distribution	narrow-beam; direct
system of protection	IP 67
class of protection	III
operation	external
housing	aluminum; anodized; jet black
cover	borosilicate
mains lead	built-in plug; 5.00 m (197")
fastening	table clamp (accessory); wall bracket (accessory); screw-down flange
color temperature	
special features	spot with 6° angle of reflected beam

illuminance

E_{min}: 69 lx
E_m: 1219 lx
E_{max}: 8966 lx

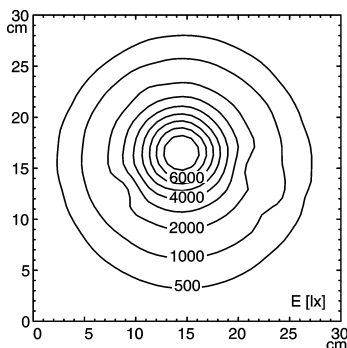

luminous intensity

