

Hubbellock® Devices
 30A, 600V AC, 20A, 250V DC, 3 Pole, 4 Wire
 Grounding

HUBBELL

Hubbellock® Receptacle

Features

- Spring loaded safety shutter contains arcing when mating or un-mating devices under load
- Spring loaded safety shutter automatically ejects the plug eliminating contact teasing
- Box terminals in conjunction with screws with pressure pads provide maximum termination strength and dependability
- Thermoset molded housing provides maximum heat resistance

Ordering Information

Description	Device Color	UPC	Catalog Number
Black phenolic	Black	783585017280	HBL20403



Specifications

Device Color	Black
Housing	Thermoset
Shutter	Thermoset
Contacts	Bronze
Bridge	Zinc plated steel
Terminal Screws	Zinc plated steel

Performance

Electrical


Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	2,000V minimum

Mechanical

Terminal Accomodation	#10 AWG - #6 AWG solid or stranded copper wire only.
Terminal Identification	Terminals identified in accordance with UL 498

Environmental

Flammability	UL 94 V0 for Receptacles and Inlets.HB or better for Plugs and Connectors
Moisture Resistance	IP30 Suitability
Operating Temperatures	Maximum Continuous 75°C; Minimum -40°C (w/o impact)

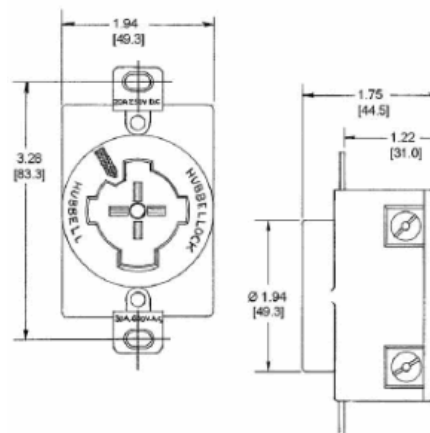

Accessories

Plug	HBL21415B
Weatherproof Lift Cover	HBL7428WOG
Single Gang Stinless Steel Wallplate	SS737

Resources

Customer Use Drawing	
eCatalog	

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

