

# Twist-Lock® Devices 20A, 250V AC, 2 Pole, 2 Wire Non-Grounding Insulgrip® Plug

# HUBBELL

## Features

- Integral dust shield protects wiring chamber from dust or contaminants.
- Self-threading screws specially designed for secure assembly
- Wiring chambers separate and positively insulate conductors and promote easy inspection

## Ordering Information

Description	Cord Diameter	UPC	Catalog Number
Black and white nylon, polarized	.230"-.720" (5.6-18.3)	783585177052	HBL7102C

## Listings

Listed to UL 499  
Fed.Spec. W-C-597  
Certified to CSA C22.2 No.43

## Specifications

Body	Nylon
Terminal Retainer	Clear polycarbonate
Contacts	Bronze
Terminal Screw	Brass
Terminal Clamp	Cold rolled steel – nickel plated
Assembly Screws	Steel - zinc plated

## Performance

### Electrical

Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum

### Mechanical


Terminal Accommodation	#16 AWG - #8 AWG stranded copper wire only.
Terminal Identification	Terminals identified in accordance with UL 498

### Environmental

Flammability	HB or better per UL94/CSA 22.2 No.0.17
Moisture Resistance	IP20 Suitability
Operating Temperatures	Maximum Continuous 75°C Minimum -40°C (w/o impact)



20A 250V  
NEMA L2-20P  
UL Listed  
2 HP

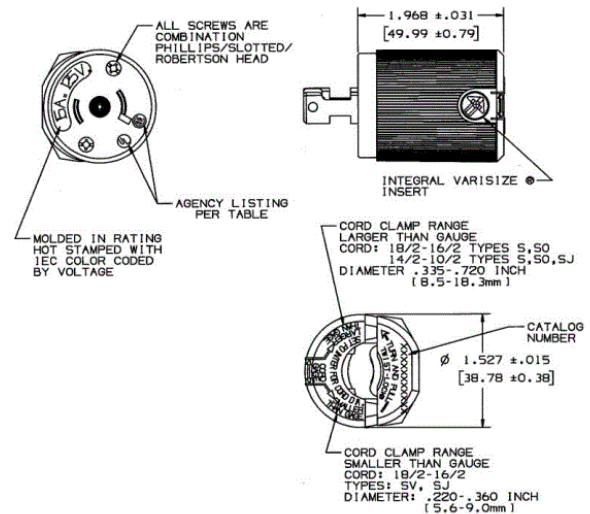

## Accessories

Connector	HBL7101C
Weatherproof Boot	HBL6023

## Resources

Customer Use Drawing  
eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

