

Non-NEMA Twist-Lock® Devices
 10A, 250V, 15A, 125V, 3 Pole, 3 Wire
 Non-Grounding
 Receptacle

HUBBELL

Features

- Reinforced thermoplastic construction
- Single piece, all brass contacts
- Single point break-off tabs
- Mounting strap tabs lock the body and base together

Ordering Information

Description	Device Color	UPC	Catalog Number
Duplex, flush, black RTP	Black	783585002354	HBL7580

Listings

Listed to UL 498
 Fed. Spec. W-C-596
 Certified to CSA C22.2 No.42

Specifications

Face	RTP
Base	RTP
Contacts	Brass
Clamp	Brass
Ground Contact	Brass
Terminal Screws	Brass

Performance

Electrical

Dielectric Voltage Withstands 2,000V minimum

Mechanical

Terminal Accommodation #18-#10 AWG solid or stranded copper wire.

Terminal Accommodation #18 AWG -#10 AWG solid or stranded copper wire only.


Terminal Identification Terminals identified in accordance with UL 498

Environmental

Flammability V2 or better per UL94/CSA 22.2 No.0.17

Moisture Resistance IP20 Suitability

Operating Temperatures Maximum Continuous 75°C; Minimum -40°C (w/o impact)

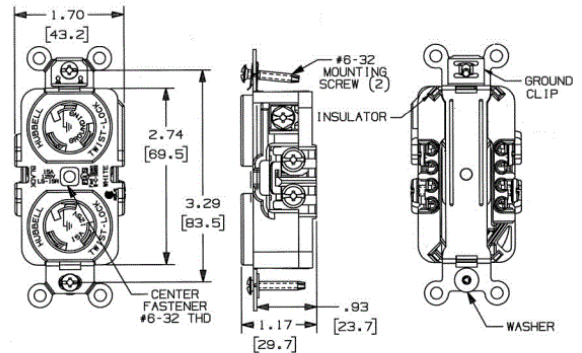

Accessories

Plug HBL7567C
 Wallplate or Weatherproof Cover Duplex Opening

Resources

Customer Use Drawing
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

