

Twist-Lock® Devices
 50A, 125V AC, 2 Pole, 3 Wire Grounding
 Receptacle

HUBBELL

Features

- Thermoset construction offers high heat resistance
- Armored housing provides superior impact resistance
- One piece contacts provide low operating temperatures

Ordering Information

Description	Device Color	UPC	Catalog Number
Phenolic	Black	783585871301	CS6370

Listings

Listed to UL 498
 Certified to CSA C22.2 No.42

Specifications

Body	Phenolic
Face	Phenolic
Contacts	Brass
Terminal Screws	Steel
Insulator	Phenolic

Performance

Electrical


Current Interrupting	Certified for current interrupting at full rated current
Dielectric Voltage	Withstands 2,000V minimum

Mechanical

Terminal Accommodation	#10 AWG - #4 AWG solid or stranded copper wire only
------------------------	---

Environmental

Flammability	UL 94 V0
Operating Temperatures	Maximum continuous 75°C; minimum -40°C (w/o impact)

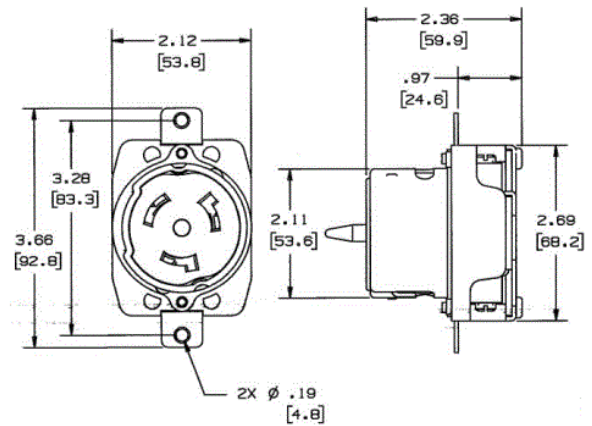

Accessories

Plug	CS6361C
Weatherproof Lift Cover	HBL7774WO
Single Gang Stainless Steel Wallplate	SS750
4" Square Raised Cover	HBL50SC

Resources

Customer Use Drawing
 eCatalog

Dimensions in Inches (mm)

Hubbell Wiring Device-Kellems • Hubbell Incorporated (Delaware) • 40 Waterview Drive • Shelton, CT 06484

Phone (800) 288-6000 • Fax (800) 255-1031 • Specifications subject to change without notice.

