


15 and 20 Ampere, 125 Volts




15A 125V
NEMA 5-15R
UL CSA
0.5 HP




20A 125V
NEMA 5-20R
UL CSA
1 HP

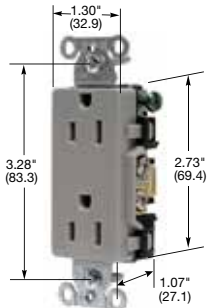


DR15GRY

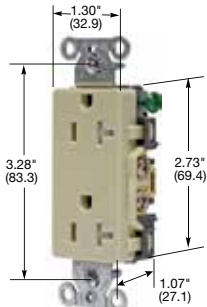


DR20ITR

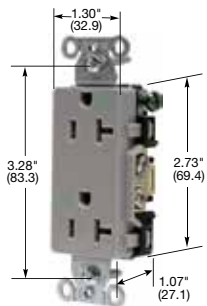

DR20GRYWRTR

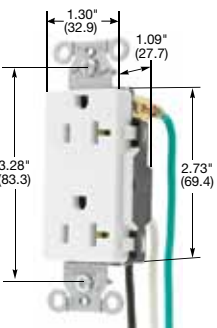

DR20WHIP2

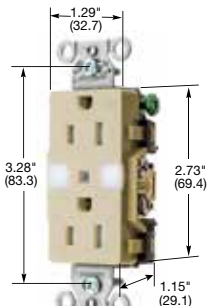

DR15NLIV

Dimensions in Inches (mm)

Commercial Specification Grade Receptacles

Style Line® Decorator

	Color	Catalog Number	
Smooth polycarbonate face, Style Line® decorator duplex, back and side wired.	Black	DR15BLK	DR20BLK
	Brown	DR15	DR20
	Gray	DR15GRY	DR20GRY
	Green	DR15GN	DR20GN
	Ivory	DR15I	DR20I
	Light Almond	DR15LA	DR20LA
	Red	DR15R	DR20R
	White	DR15WHI	DR20WHI
Tamper-Resistant, Style Line® decorator duplex, smooth polycarbonate face, back and side wired.	Black	DR15BLKTR	DR20BLKTR
	Brown	DR15TR	DR20TR
	Gray	DR15GRYTR	DR20GRYTR
	Green	DR15GNTR	DR20GNTR
	Ivory	DR15ITR	DR20ITR
	Light Almond	DR15LATR	DR20LATR
	White	DR15WHITR	DR20WHITR
Weather and Tamper-Resistant, Style Line® decorator duplex, smooth polycarbonate face, back and side wired.	Black	DR15BLKWRTR	DR20BLKWRTR
	Brown	DR15WRTR	DR20WRTR
	Gray	DR15GRYWRTR	DR20GRYWRTR
	Ivory	DR15IWRTR	DR20IWRTR
	Light Almond	DR15LAWRTR	DR20LAWRTR
	White	DR15WHIWRTR	DR20WHIWRTR
Pre-wired receptacles, Style Line® decorator duplex, smooth polycarbonate face, back and side wired, self-grounding, 8" solid wire leads.	Black	DR15BLKP1	DR20BLKP1
	Brown	DR15P1	DR20P1
	Gray	DR15GRYP1	DR20GRYP1
	Ivory	DR15IP1	DR20IP1
	Light Almond	DR15LAP1	DR20LAP1
	White	DR15WHIP1	DR20WHIP1
Pre-wired receptacles, Style Line® decorator duplex, smooth polycarbonate face, back and side wired, self-grounding, 8" stranded wire leads.	Black	DR15BLKP2	DR20BLKP2
	Brown	DR15P2	DR20P2
	Gray	DR15GRYP2	DR20GRYP2
	Ivory	DR15IP2	DR20IP2
	Light Almond	DR15LAP2	DR20LAP2
	White	DR15WHIP2	DR20WHIP2
Pre-wired receptacles, Tamper-Resistant, Style Line® decorator duplex, smooth polycarbonate face, back and side wired, self-grounding, 8" solid wire leads.	Black	DR15BLKTRP1	DR20BLKTRP1
	Brown	DR15TRP1	DR20TRP1
	Gray	DR15GRYTRP1	DR20GRYTRP1
	Ivory	DR15ITRP1	DR20ITRP1
	Light Almond	DR15LATRP1	DR20LATRP1
	White	DR15WHITRP1	DR20WHITRP1
Pre-wired receptacles, Tamper-Resistant, Style Line® decorator duplex, smooth polycarbonate face, back and side wired, self-grounding, 8" stranded wire leads.	Black	DR15BLKTRP2	DR20BLKTRP2
	Brown	DR15TRP2	DR20TRP2
	Gray	DR15GRYTRP2	DR20GRYTRP2
	Ivory	DR15ITRP2	DR20ITRP2
	Light Almond	DR15LATRP2	DR20LATRP2
	White	DR15WHITRP2	DR20WHITRP2
Nightlight receptacle, two nightlight sources for a total of 0.5 Lumens, Tamper-Resistant shutters complies with NEC article 406.12, back and side wired	Ivory	DR15NLIV	-
	Light Almond	DR15NLLA	-
	White	DR15NLWH	-

Note: See page A-47 for accessories.

See page Tech-10 for Tamper and Weather Resistant descriptions.

See section O for wallplates.