

# NEWBORN

## Accessories




**STANDARD SAUSAGE** PC-620  
**THIN SAUSAGE** PC-62  
**BENT SAUSAGE** PC-620BENT  
**NOZZLES SAUSAGE** PC-38NOZZLE, 3/8" PC-516NOZZLE, 5/16"  
**NOZZLE ADAPTER SAUSAGE** PC-ADAPTER  
**STANDARD BULK** PC-58



**BEAD BUDDY**  
 Articulating Nozzles for Sausage and Bulk

**STANDARD** BB-45

**LARGE** BG-45

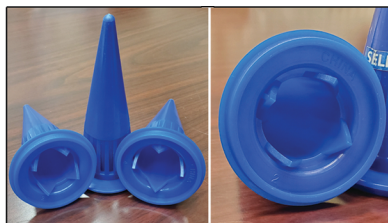


**LARGE VERSION**  
 PC-PUNCTURELG

**SELF-PUNCTURING SAUSAGE CONES**



**No Knife Needed to Cut Sausage Pack**

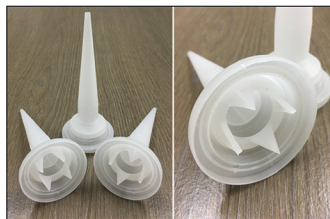

**SMALL VERSION**  
 PC-PUNCTURES



**CARTRIDGE NOZZLE**  
 12" Flexible Reach  
 PK-FLEXNOZZLE



**CAULK BUDDY**  
 CB100: Finishing tool with 2 caulk tube caps. Clips onto the frame of some cartridge guns

### PATENTED POCKET SLIX

All in one spatula set with 6 blades Widths include 5/8" tapered, 5/8", 3/4", 7/8", 1", and 1-1/2". Plastic version does not have 5/8" blades.



**STANDARD TIPS**  
 POCKETSLK.

**FLEXIBLE TIPS**  
 POCKETSLK-FLEX


**ELLIPTICAL TIPS**  
 POCKETSLK-ELP

**PLASTIC TIPS**  
 POCKETSLK-PLA



### BACKER ROD INSERTION TOOL


KIT-BRIT - Set includes tool body with threaded swivel connection for handle and 5 "skates" in the following sizes (width x depth): 3/32" x 5/16", 1/4" x 1/2", 1/2" x 1/2", 3/4" x 1/2" and 1" x 1/2"

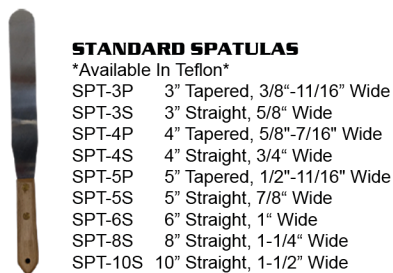

### STANDARD SPATULAS

\*Available In Teflon\*

- SPT-3P 3" Tapered, 3/8"-11/16" Wide
- SPT-3S 3" Straight, 5/8" Wide
- SPT-4P 4" Tapered, 5/8"-7/16" Wide
- SPT-4S 4" Straight, 3/4" Wide
- SPT-5P 5" Tapered, 1/2"-11/16" Wide
- SPT-5S 5" Straight, 7/8" Wide
- SPT-6S 6" Straight, 1" Wide
- SPT-8S 8" Straight, 1-1/4" Wide
- SPT-10S 10" Straight, 1-1/2" Wide

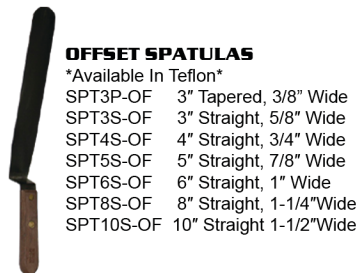

### OFFSET SPATULAS

\*Available In Teflon\*

- SPT3P-OF 3" Tapered, 3/8" Wide
- SPT3S-OF 3" Straight, 5/8" Wide
- SPT4S-OF 4" Straight, 3/4" Wide
- SPT5S-OF 5" Straight, 7/8" Wide
- SPT6S-OF 6" Straight, 1" Wide
- SPT8S-OF 8" Straight, 1-1/4" Wide
- SPT10S-OF 10" Straight 1-1/2" Wide



### SPATULA SET

\*Available In Teflon\*  
 KIT-SPT - Comes with 3" Tapered and 3", 4", 5", 6" and 8" Straight



### OFFSET SPATULA SET

\*Available In Teflon\*  
 KIT-SPT-OF - Comes with 3" Tapered and 3", 4", 5", 6" and 8" Straight




**SLICK-1**  
 Comes with 3" Tapered, 3", 4", 5", 6" and 8" Straight. Equipped with rubber grips. \*Available In Teflon\*.



**SLICK-2**  
 Comes with 3" Tapered, 3", 4", 5", 6", 8" and 10" Straight.



**SLICK-WRAP**  
 Fits full set of Slick-2

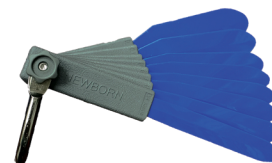

**PLASTIC SPATULA SET**  
 KIT-SPT-PLASTIC  
 Set of 8 all plastic spatulas. Both wide and aggressive tips with widths of 3/4", 7/8", 1", and 1-1/2".



**WIDE SPATULA SET**  
 KIT-SPT-WIDE - Comes with 1", 1-1/2", 2" and 3" Wide. All are 4" Long.

## PISTONS



**SAUSAGE CUP**  
SC-81



**CONICAL EJECTOR**  
CI-90



**DUAL HYTREL CUP**  
DC-81



**LEATHER CUP KITS**  
KIT-LC2 - 2"  
KIT-LC3 - 3"



**FLOATING SAUSAGE CUP**  
HFC-81



**LEATHER CUP SPREADER**  
PB-LCSP2 - 2"



**CARTRIDGE PLUNGER**  
EP-92



**LEATHER CUPS**  
LC2 - 2" rubber impregnated  
SLC2 - 2" soft  
LC3 - 3" rubber impregnated

## THE PIPEKNIFE Sealant Cutout Tools



**THE ORIGINAL**  
PK-14: 14" and PK-18: 18"



**FLAT HANDLE EXTRUDED ALUMINUM**  
LK-9: 9", LK-14: 14",  
LK-18: 18" and LK-24: 24"



**PIPEKNIFE BLADES**  
ASB - Angeled Serrated  
SB - Serrated  
LUB - Long Utility  
UB - Utility



**FLAT HANDLE STEEL**  
SLK-9: 9", SLK-14: 14", SLK-18: 18" and SLK-24: 24"



**6-IN-1 TOOL**  
PK-6IN1



**VIBRATING KNIFE BLADES**  
VKBS - Rectangular  
VKBL - Pointed

## CAPS



**BLACK LIGHTNING GLOVES**  
PK-BLKL: Nitrile, Various Sizes



**Aluminum Cap**  
FCS-820al  
Fits 820al/620al



**Plastic Cap**  
FCS-620al  
Fits 620al



**Bulk Cap**  
FCS-67  
2" Ring Cap  
FCS-68  
2 5/8" Ring Cap



**Bulk Ring Cap**  
RCP-60  
2" Ring cap for  
PC-58



**CATALYST MIXERS**  
MX-02: 4" wide x 22" tall  
MX-03: 4" wide x 28" tall



**TURBO MIXER**  
MX-01: 14" tall



**BUCKET SCRAPERS**  
SCR-02 2" Wide  
SCR-03 2-1/2" Wide



**FOLLOW PLATE**  
With neoprene seal and quick-connect O-ring  
FPT-02 - 1-1/2 / 2 gallon  
FPT-05 - 5 gallon

## BULK NOZZLES

All nozzles 3" long unless noted



**OVAL**  
OV-17: 3/16" ID  
OV-18: 1/4" ID  
OV-21: 3/8" ID  
OV-25: 1/2" ID  
OV-27: 5/8" ID



**ROUND**  
R-9: 1/8" (4" Long)  
R-10: 3/32" (4" Long)  
R-11: 1/8" (4" Long)  
RB-12: Bent 1/8" (5" Long)  
RB-16: Bent 1/8" (18" Long)  
RBS-16: 1/8" (18" Long)



**SQUARE**  
SQ-49: 1/8" x 3/8"  
SQ-50: 1/8" x 3"  
SQ-51: 1/8" x 7/8"



**BEVEL**  
BE-35: 1/8" x 3/8"  
BE-36: 1/16" x 3/8"  
BE-37: 1/16" x 5/8"  
BE-38: 1/8" x 7/8"



**TRIANGLE**  
TR-46: 3/8"  
TR-48: 7/16"  
TR-49: 1/2"

## LADDER HOOKS



**BULK GUNS**  
LH-36A



**BULK GUNS**  
LH-32



**SAUSAGE GUNS**  
LH-35A



## NEWBORN BROTHERS CO.

Main Office & Warehouse  
7222 Parkway Drive, Suite A  
Hanover, MD 21076

Other Warehouse  
Dallas, TX

CALL  
(800)638-3983  
(301)604-1500  
FAX  
(301)604-7950

