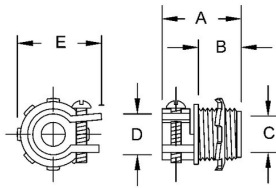


**FLEXIBLE METAL STRAIGHT SQUEEZE CONNECTORS**Straight Squeeze Connectors, Uninsulated Malleable Iron  
N/A**B61**

Catalog #: 2103

**APPLICATIONS**For use in dry locations to bond flexible metal conduit to a box or enclosure  
N/A**PRODUCT FEATURES**All malleable iron construction insures mechanical protection for the raceway  
Electro zinc plated for added corrosion protection  
UPC bar coded fittings are individually polybagged with a preprinted UPC-A bar code, and packaged in pre-scored tear top cartons for an attractive presentation**CULUS**

UL Listed E195969

**GENERAL PRODUCT INFORMATION**

Trade Size: 3/4 in.

**DRAWING DIMENSIONS**

Dimension A:	1-15/32 in.
Dimension B:	31/64 in.
Thread Spec. B:	3/4 in. - 14 NPS
Dimension C:	.763 in.
Dimension D:	1.043 - 1.122
Dimension E:	1-15/16 in.

**PACKAGING**

Package Type:	Carton
Ship Carton Qty.:	25
Product UPC-A Labeled:	No
Weight (Lbs. Per/C):	20.00
Ship Carton Length (in.):	8.25
Ship Carton Width (in.):	5.00
Ship Carton Height (in.):	4.00
Ctn Weight (Lbs.):	4.45
UPC Number:	050169021033
I2of5:	50050169021038