




GK11M

General purpose beaded tip probe

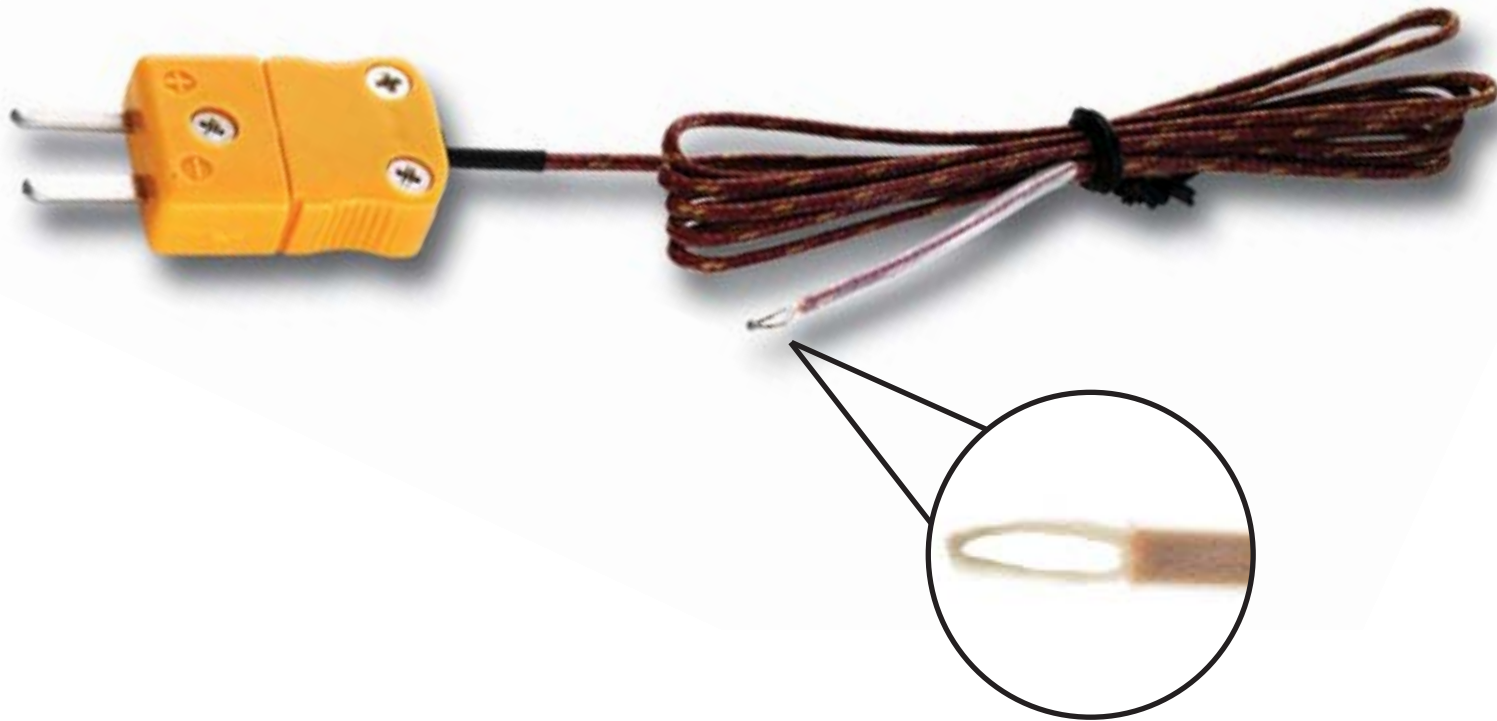

Copyright © 2007 Test Products International, Inc.

Application

Exposed junction for fast response in non-food liquid, air and surface applications

Range°F°C

-40° to 950°F
-40° to 510°C

Probe tip

42

Dimensions

Stem Length: N/A
Diameter: 28 gauge
Lead Length: 48" (1.2M)

Insulation Material

Fiberglass