

► Model A12SA

Voice Gun® Portable Loudspeaker



Take control of the situation with Federal Signal Voice Guns® —the most powerful lightweight electronic megaphones available. Specialized noise canceling microphones improve voice reproduction even at long distances. Rugged high-impact Cyclac™ parts are virtually indestructible for long service life. Ideal for industrial, fire, marine, athletics, law enforcement and many other applications.


Model A12SA is made of Lexan™ high-impact, self-extinguishing plastic. This benefit makes it appropriate for hazardous environments such as oil refineries and other industries where fire hazard is always present. The A12SA operates on eight “AA” batteries.

F E A T U R E S

- Excellent sound quality
- Trouble-free solid-state design
- Battery operated

MODEL	BATTERIES REQUIRED	POWER OUTPUT	RANGE
A12SA	(8) “AA”	16 watt	1/4 mile

Portable Loudspeaker (A12SA)

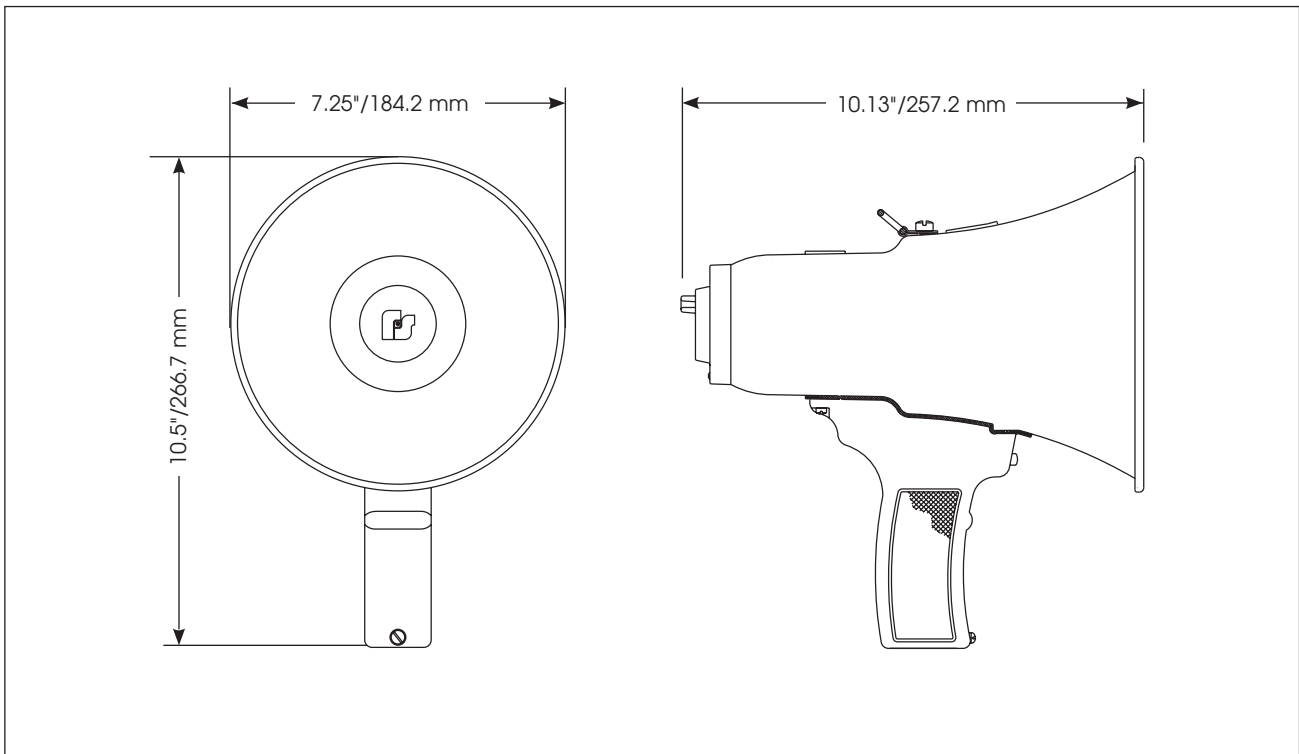

SPECIFICATIONS

Net Weight:	3.0 lbs.	1.36 kg
Length:	10.13"	257.2 mm
Height:	10.5"	266.7 mm
Diameter:	7.25"	184.2 mm

HOW TO ORDER

Specify Model:
A12SA – Voice Gun, 16 watt, red