

# Miller 8928 D-Ring Extension

Models: 8928/18INBK, 8928-Z7/18INBK

## Description

The 8928 D-ring extension snap hook connects to a full-body harness back D-ring. The D-ring on the extension allows the user to easily attach to a shock-absorbing lanyard or a self-retracting lifeline.

## ⚠ WARNING:

A Shock Absorbing Lanyard or Self Retracting Lifeline that limits forces to 900 lbs must be used.

## Materials

<b>Webbing:</b>	1 ¾ - in. (44 mm) polyester
<b>Snap Hooks:</b>	Steel, ¾ - in. (19 mm) gate opening
<b>D-Rings:</b>	Steel, 2 ¼ - in. (57 mm) opening
<b>Thread:</b>	Six-cord bonded, three strand polyester
<b>Labels:</b>	Valeron

\*All hardware meets ASTM (50) fifty-hour salt spray test requirements


## Technical

<b>Max Working Load Capacity:</b>	400 lbs (181.4 kg)
<b>Webbing:</b>	5000 lbs (22 kN) min. tensile strength
<b>D-Rings:</b>	5000 lbs (22 kN) min. tensile strength
<b>Thread:</b>	42 lbs (19 kg) min. tensile strength
<b>Length:</b>	18 inches (457 mm)

## Certification

OSHA 1926.502, 1910.66, ANSI A10.32, Z359-2007\* and CSA Z259.11

\*8928-Z7/18INBK

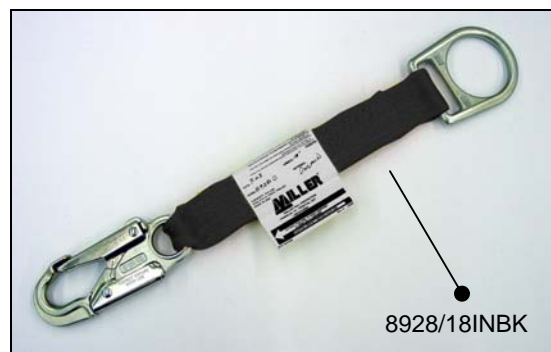

# MILLER®

by Honeywell

Toll Free 800.873.5242 (press 4) • [hsptechsupport@honeywell.com](mailto:hsptechsupport@honeywell.com) • [www.millerfallprotection.com](http://www.millerfallprotection.com)

⚠ **WARNING!** THIS DOCUMENT PROVIDES AN OVERVIEW OF FALL PROTECTION PRODUCTS AVAILABLE FROM HONEYWELL AND CARE HAS BEEN TAKEN TO ASSURE THE ACCURACY OF THE DATA. IT DOES NOT PROVIDE IMPORTANT PRODUCT WARNINGS AND INSTRUCTIONS. HONEYWELL RECOMMENDS ALL USERS OF FALL PROTECTION EQUIPMENT UNDERGO THOROUGH TRAINING, AND THAT ALL WARNINGS AND INSTRUCTIONS PROVIDED WITH THE PRODUCTS BE THOROUGHLY READ AND UNDERSTOOD PRIOR TO EACH USE. FAILURE TO READ AND FOLLOW ALL PRODUCT WARNINGS AND INSTRUCTIONS COULD RESULT IN SERIOUS INJURY OR DEATH.