

CorePro LEDtube InstantFit T8

14T8 PRO LED/48-3000 IF G 10/1

The CorePro LED Type A - Ballast Driven InstantFit TLED is a great LED solution suitable for replacing T8 fluorescent lamps, using the existing ballast. The InstantFit (Type A) lamps can also be used with Philips TLED drivers for Type C applications.

Product data

General Information	
Base	G13 [Medium Bi-Pin Fluorescent]
Nominal Lifetime (Nom)	50000 h
Switching Cycle	50000X
B50L70	50000 h
Light Technical	
Color Code	830 [CCT of 3000K]
Initial lumen (Nom)	2000 lm
Luminous Flux (Rated) (Nom)	2000 lm
Correlated Color Temperature (Nom)	3000 K
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	20000-120000 Hz
Power (Rated) (Nom)	14 W
Lamp Current (Max)	260 mA
Lamp Current (Min)	80 mA
Starting Time (Nom)	0.5 s


Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.9
Voltage (Nom)	120-277, 347 V
Temperature	
T-Ambient (Max)	45 °C
T-Ambient (Min)	-20 °C
T-Storage (Max)	65 °C
T-Storage (Min)	-40 °C
T-Case Maximum (Nom)	50 °C
Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Product Length	1200 mm
Approval and Application	
Energy Efficiency Label (EEL)	Not applicable
Energy Saving Product	Yes

CorePro LEDtube InstantFit T8

Approbation Marks	UL certificate RoHS compliance DLC compliance
Product Data	
Order product name	14T8 PRO LED/48-3000 IF G 10/1
EAN/UPC - Product	046677452407
Order code	470096

Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	10
Material Nr. (12NC)	929001343004
Net Weight (Piece)	0.215 kg
Model Number	9290013430


Dimensional drawing

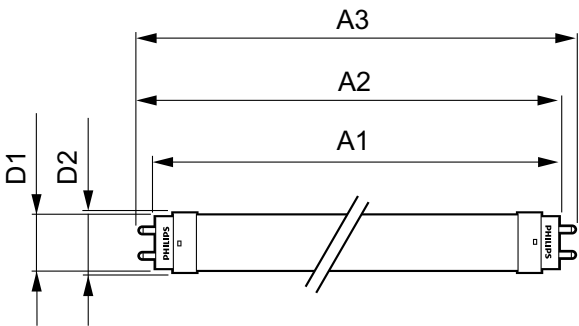


14T8 PRO LED/48-3000 IF G 10/1

Product	D1	D2	A1	A2	A3
14T8 PRO LED/48-3000 IF G 10/1	25.7 mm	28 mm	1198 mm	1205 mm	1212 mm


Photometric data

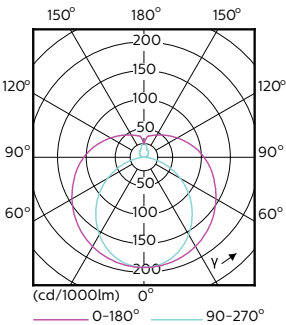

LEDtube 1200mm 17W G13 2100lm

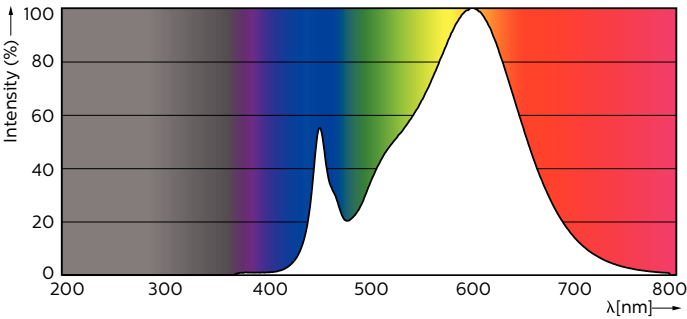

LEDtube PRO 1200mm 14W G13 830 2000lm


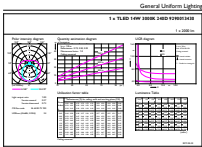


General Uniform Lightness

LEDtube PRO 1200mm 14W G13 830 2000lm



CorePro LEDtube InstantFit T8

Lifetime

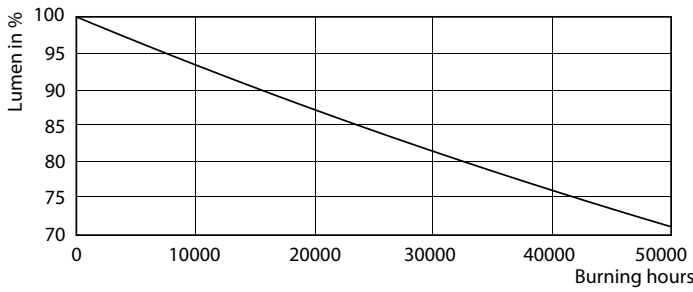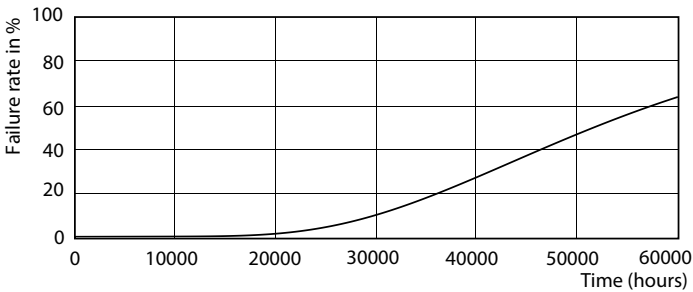


LEDtube PRO 1200mm 14W G13 2000lm

LEDtube PRO 1200mm 14W G13 2000lm

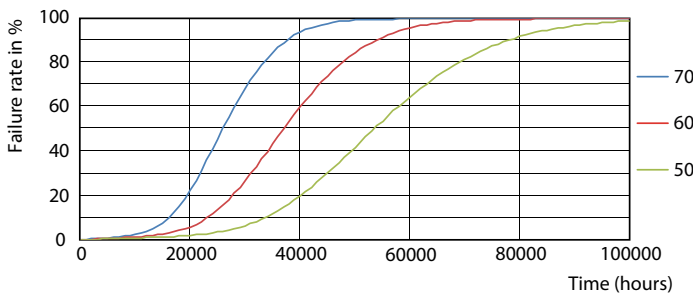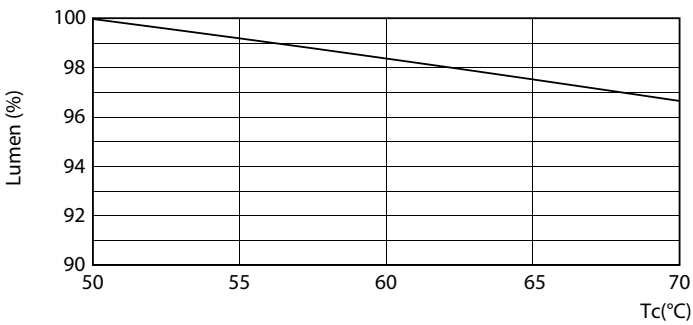

12W G13

12W G13

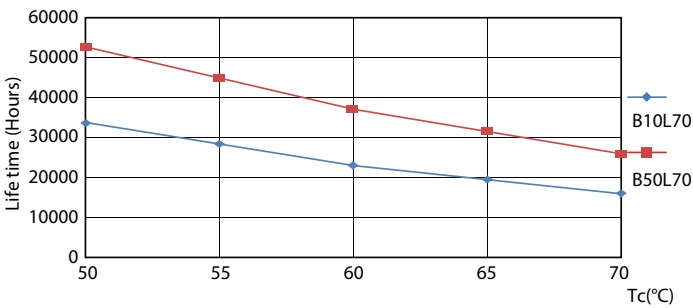

12W G13

CorePro LEDtube InstantFit T8

