
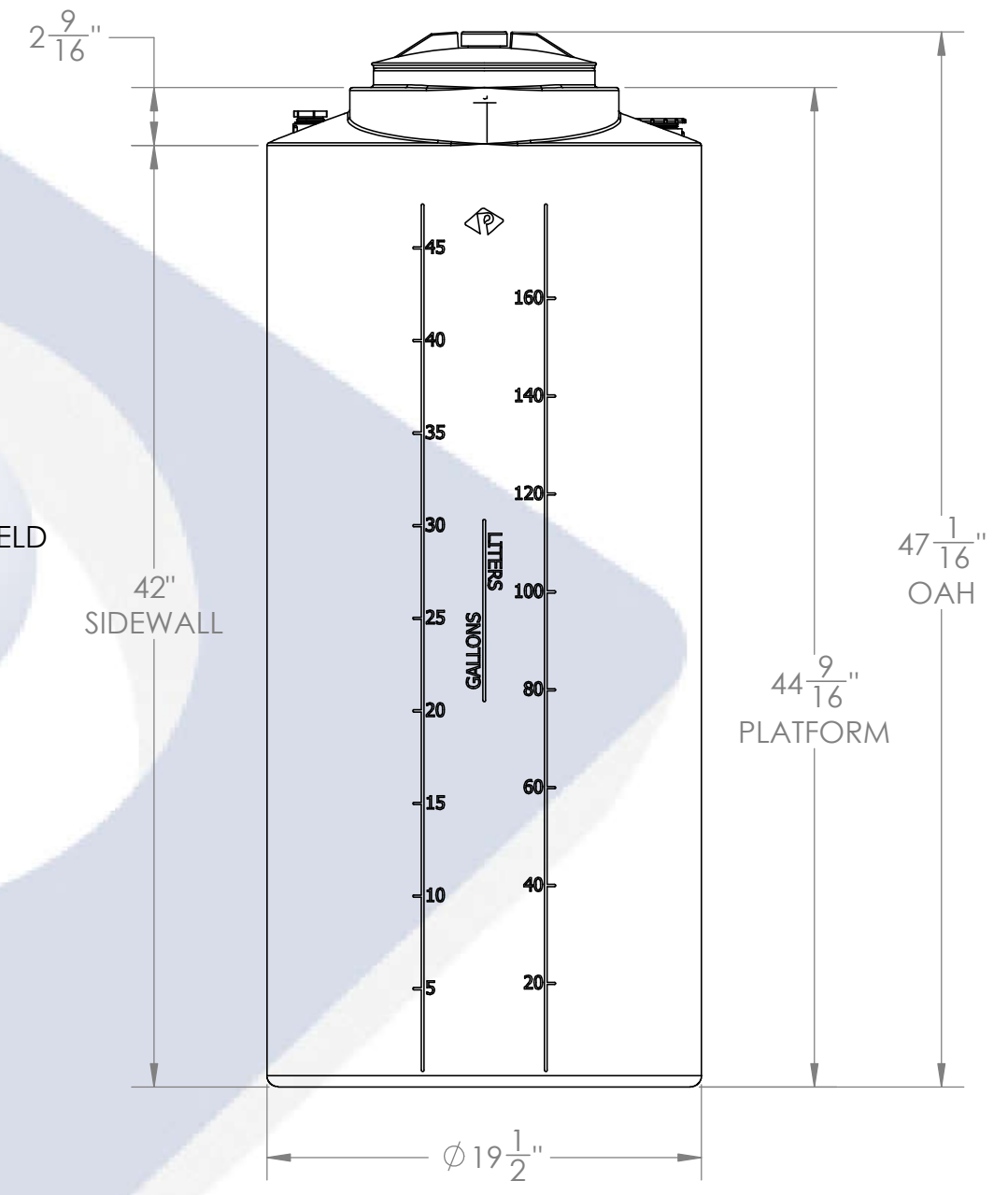
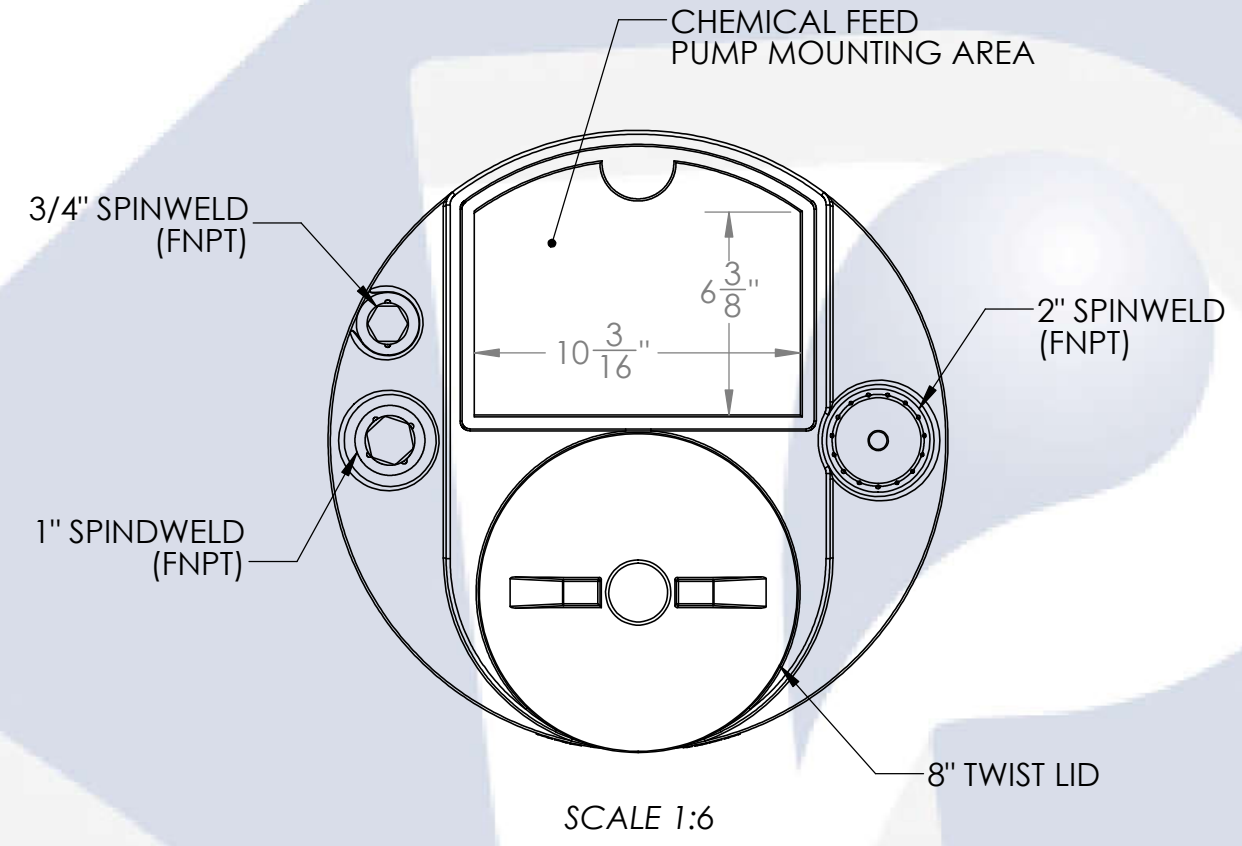


8 7 6 5 4 3 2 1

D  
C  
B  
A

D  
C  
B  
A

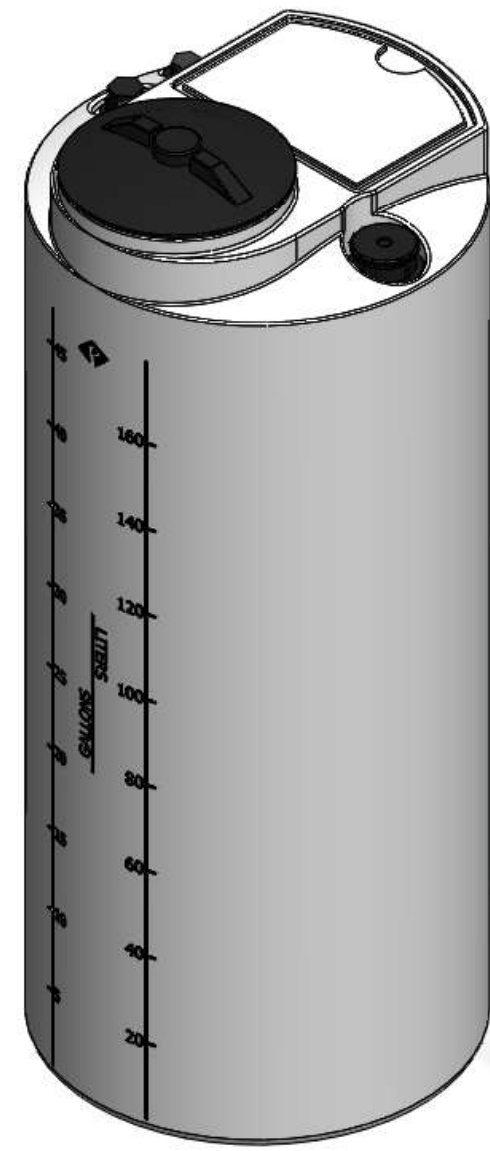

50G PROCHEM TANK	
MATERIAL	PART NUMBER
LLDPE, NATURAL, 1.9 SPG	01-31263
XLPE, NATURAL, 1.9 SPG	01-31323
LLDPE, FDA BLACK, 1.0 SPG	01-31865

- NOTES:**
- CAPACITY: 50 GAL. NOMINAL
  - TANK MATERIAL OPTIONS  
LLDPE HDLPE XLPE FDA WATER PPL PVDF
  - SERVICE PRESSURE: ATMOSPHERIC
  - NSF/ANSI STANDARD 61 CERTIFIED
  - AVAILABLE W/ FRP WRAP  
CONTACT CUSTOMER SERVICE FOR ADDITIONAL INFORMATION

**PROPRIETARY AND CONFIDENTIAL**  
THE INFORMATION CONTAINED IN THIS DRAWING IS THE SOLE PROPERTY OF PEABODY ENGINEERING. ANY REPRODUCTION IN PART OR AS A WHOLE WITHOUT THE WRITTEN PERMISSION OF PEABODY ENGINEERING IS PROHIBITED.

UNLESS OTHERWISE SPECIFIED:		NAME	DATE	
DIMENSIONS ARE IN INCHES		DRAWN	RFR 03/29/17	
TOLERANCES: ±1/4"		CHECKED		
ANGULAR: ±.5°		ENG APPR.		
ONE PLACE DECIMAL: ±.25		MFG APPR.		
TWO PLACE DECIMAL: ±.125		Q.A.		PROJECT: PROCHEM® TANKS
THREE PLACE DECIMAL: ±.063				CUSTOMER: PEABODY STANDARD
TANK MATERIAL:				SITE/LOCATION: -
INNER TANK S/N:				DRAWING#: SEE TABLE
OUTER TANK S/N:				SIZE B
CUSTOMER PO#				DESC. 50 GAL PROCHEM® TANK, Ø19.5" x 47"
				REV. C2
DO NOT SCALE DRAWING				SCALE: 1:8
				SHEET 1 OF 1

8 7 6 5 4 3 2 1