



**MCR
SAFETY**

96720NF

Memphis

Cut Protection Specification Sheet

PRODUCT DESCRIPTION:

Cool cut protection. Dyneema® is extremely cool to work in and offers the best abrasion resistance of the high performance fibers. The 96720NF features a 13 gauge Dyneema®/Synthetic shell with a nitrile foam coating on the Palm and Fingertips.

FEATURES:

- Breathable Dyneema® shell for maximum comfort
- Encourages workers to wear their gloves longer thereby reducing injuries
- Color coded hem sizing for easy identification
- Individually poly bagged by the pair and sold by the dozen

APPLICATIONS:

Automotive Assembly, Bottling, Canning, Glass handling, HVAC, Sheet metal industry



TECHNICAL DATA FOR: 96720NF

Series	Memphis	EN 388 : CE Score - Abrasion	4
Material Group	Strings	EN 388 : CE Score - Cut	3
Product Type	Cut Protection	EN 388 : CE Score - Tear	4
Glove Size	Large	EN 388 : CE Score - Puncture	3
Gauge	13 Gauge	ANSI Cut	ANSI Cut A3
Material	Dyneema	ANSI Abrasion	ANSI Abrasion 5

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved




MCR
SAFETY

96720NF

Memphis

Cut Protection Specification Sheet

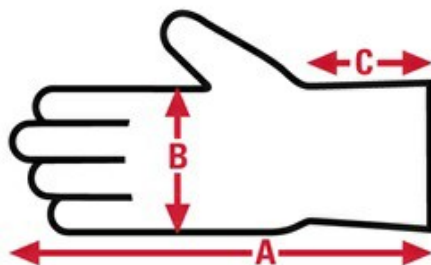

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
96720NFL	Large	13.39	4.64	3.35	29.916 lb.	2.493
96720NFM	Medium	12.80	4.72	3.15	27.276 lb.	2.273
96720NFS	Small	12.40	4.20	3.15	24.528 lb.	2.044
96720NFXL	X - Large	13.79	5.03	3.35	31.404 lb.	2.617
96720NFXS	X - Small	11.80	3.93	2.95	22.680 lb.	1.890
96720NFXXL	XX - Large	14.18	5.19	3.35	33.012 lb.	2.751

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved