


# DEWALT®

**20V** MAX\*  
LITHIUM ION

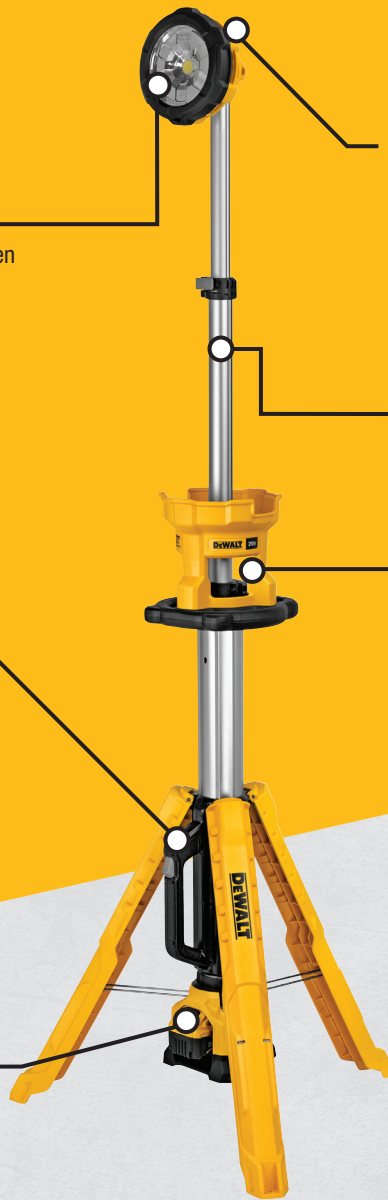

**EFFICIENT LED**  
Eliminates the heat of halogen  
Provides up to 3000 lumens

**ROTATING, PIVOTING HEAD**  
Directs light where needed

**TELESCOPING POLE  
EXTENDS OVER 7 FEET**  
Reduces shadows in work area

**EASE OF USE**  
Convenient carry handle  
Sets up in seconds

**3 BRIGHTNESS LEVELS**  
Customize workspace lighting

**CORDLESS CONVENIENCE**  
Compatible with all DeWALT  
20V MAX\* and FLEXVOLT® batteries

\*Maximum initial battery voltage (measured without a workload) is 20 volts. Nominal voltage is 18.

OVER **11 HOUR**  
**RUNTIME**  
WITH DCB206 BATTERY,  
LOW SETTING

**3000** LUMENS  
**MAX BRIGHTNESS**

**IP-55**  
DUST, WATER, AND IMPACT  
RESISTANT

**20V MAX\* CORDLESS TRIPOD LIGHT**

**DCL079**



› Cordless Convenience



› Stand extends over 7 feet

## SPECIFICATIONS

<b>Height</b>	7+ feet
<b>IP</b>	55
<b>Brightness Levels†</b>	High 3+ hours Med 6+ hours Low 11+ hours

†With DCB206 battery

### TOOL WARRANTY

<b>3</b> YEAR	<b>1</b> YEAR	<b>90</b> DAY
LIMITED WARRANTY	FREE SERVICE	MONEY BACK GUARANTEE

**20V** MAX<sup>+</sup>  
LITHIUM ION

**100+** PRODUCTS

OUR FASTEST GROWING SYSTEM

**1-800-4-DEWALT**

**www.DEWALT.com**

Copyright ©2018 DeWALT. The following are trademarks for one or more DeWALT power tools, accessories, anchors and concrete adhesives: The yellow and black color scheme; the "D"-shaped air intake grill; the array of pyramids on the handgrip; the kit box configuration; and the array of lozenge-shaped humps on the surface of the tool.

ICDCL079SS