



Model SLM100 shown with mounting base options (ordered separately)



► Model SLM100

StreamLine® Modular Multifunctional LED Beacon

Model SLM100 offers a multifunctional LED beacon with high optical performance. Developed with a multiple input technology, Model SLM100 allows three separate light effects (steady, flashing or rotating) controllable via independent electric contacts.

The steady light option offers a conspicuous and consistent light signal. The flashing mode consists of a triple-flash strobe effect ideal for all applications where an immediate attention gain is mandatory. And, the rotating light offers a traditional rotating beacon effect without moving parts, which enhances product life.

Model SLM100 body material is a self extinguishing polycarbonate material with high impact and UV resistance suitable for outdoor applications.

FEATURES

- Compatible with 12-24VAC/DC or 120-240VAC*
 - PLC compatible with PNP or NPN connections*
 - Three separate inputs: steady, flashing or rotating
 - 50,000 hour LED
 - Five lamp/lens colors: Amber, Blue, Clear, Green and Red
 - Five mounting base options
 - Type 4X, IP66 enclosure
 - CE Compliant
 - UL and cUL listed
- * Voltage and PLC connections are dependent on selected base.

MODEL	VOLTAGE	FLASH RATE/MINUTE	ROTATIONS PER MINUTE
SLM100 *	12-24VAC/DC or 120-240VAC	85 (+/-10)	140 (+/-10)

* Indicates color: (A) Amber, (B) Blue, (C) Clear, (G) Green or (R) Red

MAXIMUM OPERATING CURRENT (mA)					
12VDC	24VDC	12VAC	24VAC	120VAC	240VAC
300	150	510	360	100	70

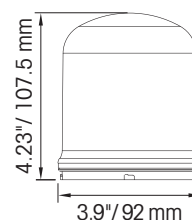
StreamLine® Modular Multifunctional LED Beacon (SLM100)

SPECIFICATIONS






Lamp Life:	50,000 Hours	
Light Source:	LED Array	
Operating Temperature:	-22°F to 122°F	-30°C to 50°C
Weight (unit(s) + base = total weight)		
SLM100	7.05 oz	0.20 kg
Shallow Base	2.12 oz	0.06 kg
Deep Base		
12-24 VAC/DC	4.23 oz	0.12 kg
120-240 VAC	6.0 oz	0.17kg
Wall Mount		
12-24 VAC/DC	6.70 oz	0.19 kg
120-240 VAC	8.47 oz	0.24 kg
Pipe Mount		
12-24 VAC/DC	5.29 oz	0.15 kg
120-240 VAC	6.70 oz	0.19 kg
Twin Wall Mount		
12-24 VAC/DC	9.17 oz	0.26 kg
120-240 VAC	12.35 oz	0.35 kg

HOW TO ORDER

- Specify model number SLM100 and color
- Specify required mounting base (see chart)
- Optional dome guard
For shallow mounting base (SLMDG3)
For deep mounting base (SLMDG4)
- Accessories for Twin and Wall Mount Bases
Cable Gland, M20, Gray, 2 Pack (K77700416)
Cable Gland, M20, Red, 2 Pack (K77700416-01)
- Accessories for Pipe Mount Base
1" NPT Adapter (SLMNPT1)
1/2" NPT Adapter (SLMNPT2)



MOUNTING BASE OPTIONS

	Model Number	Base Color	Voltage	
 Shallow Base	SLMBS-012-024GY	Gray	12-24VAC/DC	
 Deep Base	SLMBD-012-024GY	Gray	12-24VAC/DC	
	SLMBD-PNP-012-024GY	Gray	12-24VAC/DC	
	SLMBD-012-024R	Red	12-24VAC/DC	
	SLMBD-120-240GY	Gray	120-240VAC	
	SLMBD-120-240R	Red	120-240VAC	
 Wall Mount	SLMBW-012-024GY	Gray	12-24VAC/DC	
	SLMBW-PNP-012-024GY	Gray	12-24VAC/DC	
	SLMBW-120-240GY	Gray	120-240VAC	
 Pipe Mount	SLMBP-012-024GY	Gray	12-24VAC/DC	Pipe Mount comes standard with 1/2" NPT Adapter
	SLMBP-PNP-012-024GY	Gray	12-24VAC/DC	
	SLMBP-120-240GY	Gray	120-240VAC	
 Twin Wall Mount	SLMBT-012-024GY	Gray	12-24VAC/DC	
	SLMBT-PNP-012-024GY	Gray	12-24VAC/DC	
	SLMBT-120-240GY	Gray	120-240VAC	