



Model SLM800 shown with mounting base options
(ordered separately)

► Model SLM800

StreamLine® Modular High-Output Electronic Sounder

Model SLM800 is a high-output multifunctional electronic sounder developed with a multiple input technology that is capable of producing two different tones (pre-alarm, alarm) controllable via independent electric contacts.

Model SLM800 offers a high acoustic performance through 2 channels offering 64 tones, 32 tones per input selectable via dip switch. Both channels offer a powerful electronic tone adjustable from 65 dBa up to 115 dBa @ 1 meter.

Model SLM800 body material is a self extinguishing polycarbonate material with high impact and UV resistance suitable for outdoor applications.

FEATURES

- Compatible with 12-24VAC/DC or 120-240VAC*
 - PLC compatible with PNP or NPN connections*
 - Produces two tones
 - Choice of 64 selectable tones
 - 115 dBa @ 1m, adjustable volume minimum of 65 dBa
 - Type 3R, IP65 enclosure
 - CE Compliant
 - UL and cUL listed
- * Voltage and PLC connections are dependent on selected base.

MODEL	VOLTAGE	DECIBELS 1M		MAXIMUM OPERATING CURRENT (mA)			
		MIN.	MAX.	12VAC/DC	24VAC/DC	120VAC	240VAC
SLM800 *	12-24VAC/DC	65	115	240	280	–	–
	120-240VAC	65	111	–	–	60	35

*For body color, indicate GY for Gray or R for Red.


StreamLine® Modular High Output Electronic Sounder (SLM800)

SPECIFICATIONS


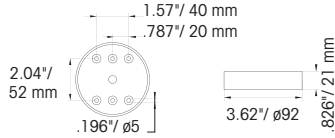

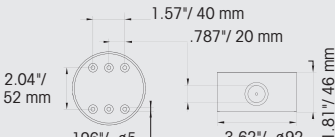

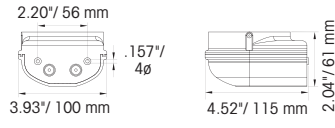

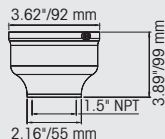

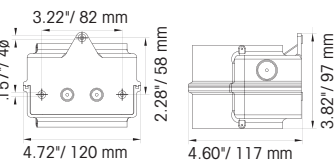
Operating Temperature:	-22°F to 122°F -30°C to 50°C	
Weight (unit(s) + base = total weight)		
SLM800	19.05 oz	0.54 kg
Shallow Base	2.12 oz	0.06 kg
Deep Base		
12-24VAC/DC	4.23 oz	0.12 kg
120-240VAC	6.0 oz	0.17kg
Wall Mount		
12-24VAC/DC	6.70 oz	0.19 kg
120-240VAC	8.47 oz	0.24 kg
Pipe Mount		
12-24VAC/DC	5.29 oz	0.15 kg
120-240VAC	6.70 oz	0.19 kg
Twin Wall Mount		
12-24VAC/DC	9.17 oz	0.26 kg
120-240VAC	12.35 oz	0.35 kg

HOW TO ORDER

- Specify model number:
SLM800GY – Gray body
SLM800R – Red body
- Specify required mounting base (see chart)
- Optional dome guard
SLMDG1 – For shallow mounting base
SLMDG2 – For deep mounting base
- Accessories for Twin and Wall Mount Bases
K77700416 – Cable Gland, M20, Gray, 2 Pack
K77700416-01 – Cable Gland, M20, Red, 2 Pack
- Accessories for Pipe Mount Base
SLMNPT1 – 1" NPT Adapter
SLMNPT2 – 1/2" NPT Adapter

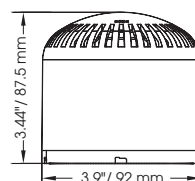

MOUNTING BASE OPTIONS

	Model Number	Base Color	Voltage	
 Shallow Base	SLMBS-012-024GY	Gray	12-24VAC/DC	
 Deep Base	SLMBD-012-024GY	Gray	12-24VAC/DC	
	SLMBD-PNP-012-024GY	Gray	12-24VAC/DC	
	SLMBD-012-024R	Red	12-24VAC/DC	
	SLMBD-120-240GY	Gray	120-240VAC	
 Wall Mount	SLMBW-012-024GY	Gray	12-24VAC/DC	
	SLMBW-PNP-012-024GY	Gray	12-24VAC/DC	
	SLMBW-120-240GY	Gray	120-240VAC	
 Pipe Mount	SLMBP-012-024GY	Gray	12-24VAC/DC	Pipe Mount comes standard with 1/2" NPT Adapter 
	SLMBP-PNP-012-024GY	Gray	12-24VAC/DC	
	SLMBP-120-240GY	Gray	120-240VAC	
 Twin Wall Mount	SLMBT-012-024GY	Gray	12-24VAC/DC	
	SLMBT-PNP-012-024GY	Gray	12-24VAC/DC	
	SLMBT-120-240GY	Gray	120-240VAC	