
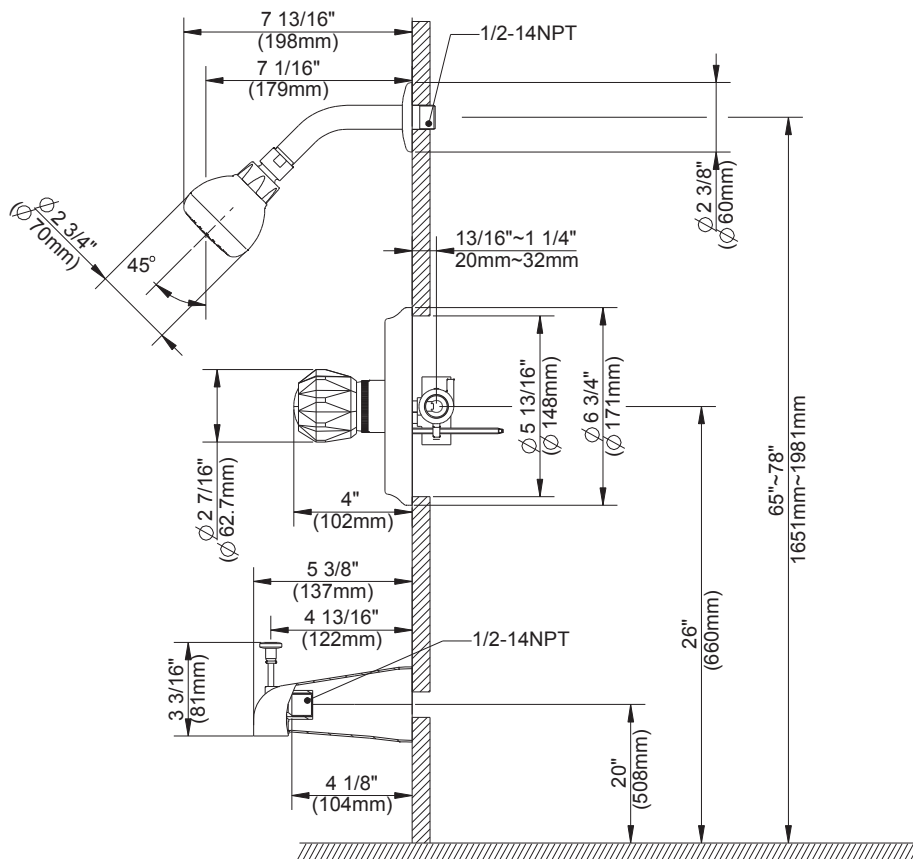


SINGLE HANDLE

TUB & SHOWER

Features:

- Acrylic handle
- Washerless cartridge
- Max Flow Rate: 1.75 gpm (6.6 L/min) at 80 psi
- One setting 3" plastic showerhead
- Non-pressure balanced valve

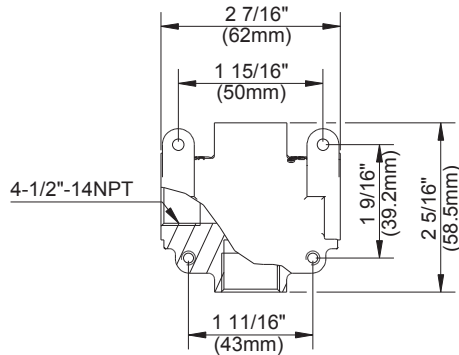


Traditional Collection



10048
Chrome Finish



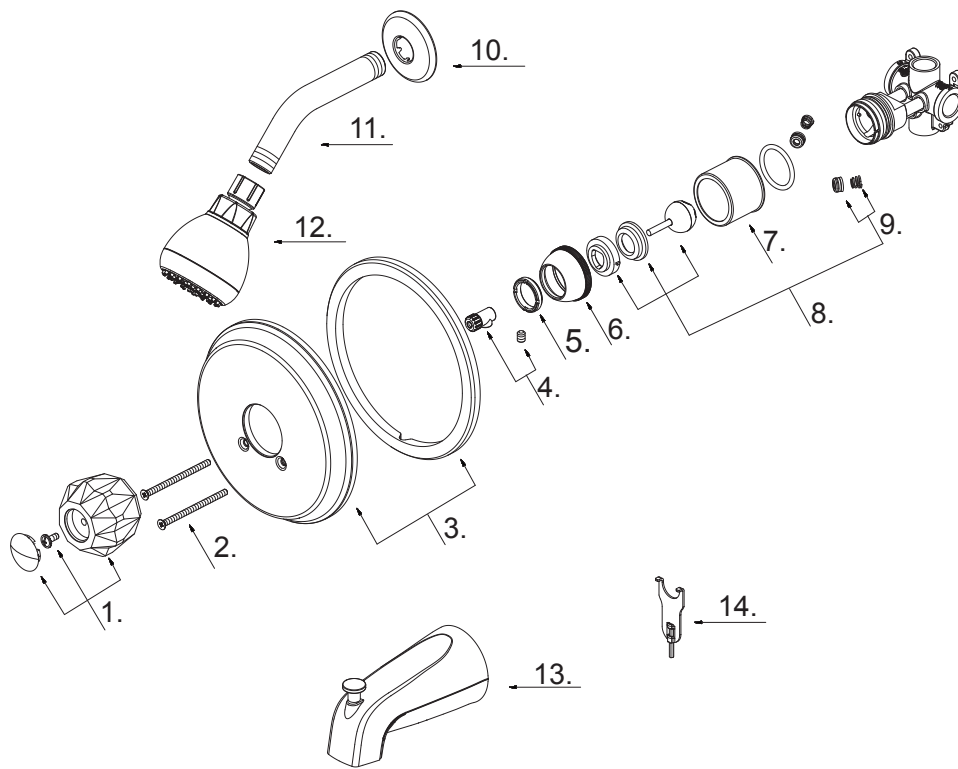

Traditional Collection



10048
Chrome Finish

1	Acrylic Handle Assembly	A662002
2	Screw Set (3/16" -24 * 2-15/16" L)	A668209
3	Escutcheon Assembly	A66F074
4	Handle Adaptor	A663024
5	Adjusting Ring	A104001
6	Trim Ring	A103000
7	Sleeve	A217000
8	Ball Valve Assembly	A66D641N
9	Seat & Spring Set	A663002
10	Shower Arm Flange	A019001-S
11	Shower Arm	A020002-S
12	Shower Head 1.75gpm	S1213300
13	Spout W/Diverter(Threaded)	A100012
14	Adjusting Ring Wrench	A031001NI

