

# DEWALT

## GUARANTEED TOUGH.

**20v MAX\***  
LITHIUM ION BRUSHLESS **XR**

## DCH273P2 SDS ROTARY HAMMER

**PERFORM  
PROTECT™**

DeWALT's Perform & Protect™ line of Power Tools is designed to provide a high level of one or more of the following: control, dust containment, or low vibration, without sacrificing performance.

**SHOCKS™**

**2  
YEAR FREE  
SERVICE**

SHOCKS™ active vibration control reduces vibration at the handles compared to hammers without this system.

**ONLY 6.6 m/s<sup>2</sup> VIBRATION**  
for improved comfort during extended operating periods†



**2.1 JOULES\*\***  
OF IMPACT ENERGY

**BRIGHT WHITE LED  
WITH DELAY FEATURE**  
helps to provide visibility

**DUST EXTRACTION  
CAPABILITY**  
D25303DH sold  
separately



**EXTREME RUNTIME WITH BRUSHLESS  
MOTOR AND 5.0 Ah BATTERIES**


**BRUSHLESS  
MOTOR**

**ADJUSTABLE  
UTILITY HOOK**  
to suspend tool  
from ladder or cart

### DCH273B - 20V MAX\* SDS ROTARY HAMMER (Tool only)



### FOR OPTIMAL USE POWERS® FASTENERS 5/32" - 1/2"

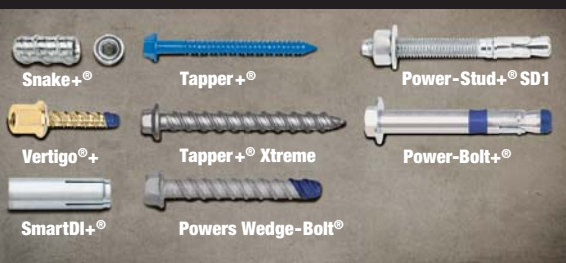

### TOOL WARRANTY

<b>3 YEAR</b> LIMITED WARRANTY	<b>2 YEAR</b> FREE SERVICE	<b>90 DAY</b> MONEY BACK GUARANTEE
--	--------------------------------------	--

### BATTERY WARRANTY

<b>3 YEAR</b> LIMITED WARRANTY	<b>3 YEAR</b> FREE SERVICE
--	--------------------------------------

\*With respect to the 20V MAX: Maximum initial battery voltage (measured without a workload) is 20 volts. Nominal voltage is 18.

\*\*According to EPTA-Procedure 05/2009. †Compared to hammers without vibration control.



# DEWALT®

## GUARANTEED TOUGH.®

### D25303DH DUST EXTRACTOR FOR 20V MAX\* SDS HAMMER



DeWALT's Perform & Protect™ line of Power Tools is designed to provide a high level of one or more of the following: control, dust containment, or low vibration, without sacrificing performance.



REPLACEABLE DUST NOZZLE

UP TO 5/8" DIAMETER CARBIDE DRILL BIT MAY BE USED

EXTREMELY TOUGH AND VERSATILE meets the needs of demanding applications

FOR USE WITH DCH273 sold separately



### HEPA Filter

#### HIGH EFFICIENCY FILTER MATERIAL

High efficiency filter material removes 99.97% of airborne particles 0.3 microns or greater

#### DURABLE CLEAR HIGH CAPACITY DUST BOX for user productivity

#### TOOL WARRANTY

<b>3</b> YEAR	<b>1</b> YEAR	<b>90</b> DAY
LIMITED WARRANTY	FREE SERVICE	MONEY BACK GUARANTEE

\*With respect to the 20V MAX: Maximum initial battery voltage (measured without a workload) is 20 volts. Nominal voltage is 18.

QUICK RELEASE for easy tool assembly

Dealer Stamp

# 1-800-4 DEWALT®

## www.DEWALT.com

Copyright ©2015 DEWALT. The following are examples of trademarks for one or more DeWALT power tools and accessories: The yellow and black color scheme; the "D"-shaped air intake grill; the array of pyramids on the handgrip; the kit box configuration; and the array of lozenge-shaped humps on the surface of the tool.