



PRODUCT SPECIFICATION REPORT



GreenLink Neutral Floor Cleaner is low foam, general purpose cleaner designed for use on most floors including finished floors. Excellent for use in automatic scrubbers. Rinses easily, leaving a film free surface. Neutral pH will not harm floor finishes.

GREENLINK™ NEUTRAL FLOOR CLEANER

PROD.#1914

Green Seal™ Certified Neutral pH Floor and General Purpose Cleaner

FEATURES/BENEFITS



Green Seal™ Certified	This product meets Green Seal™ Environmental Standard for Industrial and Institutional Cleaners, GS-37
Neutral pH	Does not contain aggressive alkaline chemicals which can dull floor finishes and harm sensitive surfaces.
Low Foam	Can be used in an automatic scrubber; rinses easily leaving a film-free surface.
Concentrated	Highly concentrated with dilutions of 1/2 - 2 oz per gallon of water for economical use.
Biodegradable	The surfactants in the products are biodegradable which can be broken down into minerals, water and carbon dioxide
No Phosphates	Does not contribute to the phosphate levels in the waste streams which are monitored by the customer's local authorities.



APPLICATIONS

Use a cotton mop for cleaning floors manually, use in automatic floor scrubbing equipment, or use as a general purpose cleaner. Particularly useful in: Airport Terminal Services, Office Buildings, Cafeterias/Restaurants, Sports & Recreational Services, Hotels & Motels, Department Stores, Nursing Homes & Hospitals, Supermarkets Schools & Educational Services

COMPANION PRODUCTS

Verdiza (GreenLink), GreenLink Floor Finish, GreenLink Floor Stripper, Multi-Clean Green (GreenLink), Spree, ESP (GreenLink), Foam San (GreenLink), Lemongrass Hand Lotion (GreenLink), Tranquil Meadows (GreenLink), DZ-7 (GreenLink)

SPECIFICATIONS

Physical form	Liquid
Color	Green
Fragrance	Mild (No Fragrance Added)
Specific Gravity	1.03
pH (concentrate)	8.0-8.5
pH (dilute 1:64)	7.5-8.0
Shelf life	1 Year Minimum
DOT shipping label	None

PACKAGING

Gallons
5 gallon pail

Zep Sales & Service
www.zep.com
1-877 I BUY ZEP

GreenLink™ is a trademark of Zep Inc and not a third party certification. GreenLink™ identifies those products meeting Zep's own standards for environmentally preferable products that, among other product-specific criteria, do not contain chlorine bleach, ammonia, ozone depleting ingredients, carcinogens, "butyl" solvent, chlorinated solvents, APE's (Alkylphenol Ethoxylates), reproductive toxins, heavy metals, and phthalates. For more information please visit www.zep.com.



LABEL SPECIMEN



GREEN PRODUCTS THAT WORK

GREENLINK™ NEUTRAL FLOOR CLEANER

PROD.#1914

BEFORE USING THIS PRODUCT, PLEASE READ THIS ENTIRE LABEL. • ANTES DE UTILIZAR ESTE PRODUCTO, POR FAVOR LEA COMPLETAMENTE ESTA ETIQUETA

Meets the Green Seal™ GS-37 Environmental Standard for industrial and institutional cleaners. Low foam, General purpose cleaner designed for use on most floors. Excellent for use in automatic scrubbers. Rinses easily, leaving a film free surface. Neutral pH will not harm floor finishes. VOC free. Alkyl phenol ethoxylate (APE) free.

DIRECTIONS:

- For Manual Cleaning:
1. Remove loose dirt with untreated dust mop.
 2. In a mop bucket, dilute product with water from cold tap at 1:256 (1/2 oz/gallon) up to 1:64 (2 oz/gallon) depending upon degree of soil.
 3. Damp mop floor.
 4. Allow floor to dry thoroughly.
- For Autoscrubbing:
1. Remove loose dirt with untreated dust mop.
 2. Place product in the autoscrubber at a dilution ratio of 1:256 (1/2 oz/gallon) up to 1:64 (2 oz/gallon) depending upon degree of soil.
 3. Select the appropriate floor pad; typical pad choice will be red or lighter.
 4. Make one pass over the floor with the autoscrubber, cleaning and picking up used solution in the same pass.
 5. Allow floor to dry thoroughly.

Undiluted product may damage some surfaces. No Fragrance Added.



Undiluted product causes eye irritation. Undiluted product may cause skin irritation. Avoid contact with skin and eyes. DO NOT swallow this product. Further information on the effects of overexposure is included on the Material Safety Data Sheet, which is available upon request from your employer. Zep advocates limiting exposure to all chemical products. Zep recommends wearing goggles or safety glasses during product use and handling. The use of rubber, neoprene, nitrile, or other resistant gloves is recommended for prolonged use. Remove contaminated clothing promptly and DO NOT rewear until thoroughly cleaned. After handling, wash hands thoroughly with soap and water.

FIRST AID:

- EYES:** Immediately flush eyes with plenty of water for at least 15 minutes, occasionally lifting the upper and lower eyelids. Get medical attention immediately.
- SKIN:** Flush affected skin with plenty of water. Consult a physician if irritation develops.
- INHALATION:** If symptoms occur, move exposed person to fresh air. If symptoms persist, get medical attention.
- INGESTION:** If this product is swallowed, DO NOT induce vomiting. If affected person is conscious give plenty of water to drink. Call a poison control center or doctor immediately for treatment advice.
- DISPOSAL AND/OR SPILL INFORMATION:** Dispose of any excess or unused product in accordance with applicable federal, state and local regulations. As with all cleaning and maintenance procedures, run-off from the cleaning or maintenance process should be diverted to a collection vessel or where permitted, to a sanitary sewer (consult local and state regulations) and not allowed to soak into the ground or to enter a storm sewer. If this product is spilled or contaminated and cannot be used creating the need for disposal, absorb product on an inert absorbent material, such as Zep-O-Zorb or Zep Zorbent, and deposit in a sealable container. Rinse area well with water. Empty product containers may be recycled in areas where community recycling programs are available.
- STORAGE:** Keep this product away from food and food products. Store tightly closed container in dry area at temperatures between 40°F (4°C) and 120°F (49°C).

KEEP OUT OF REACH OF CHILDREN FOR INDUSTRIAL AND INSTITUTIONAL USE ONLY NOT FOR HOUSEHOLD USE OR RESALE

Contains: Water: 7332-18-5; Dipropylene glycol propyl ether: 29911-27-1; C12-16 Alcohols ethoxylated 7EO: 68551-12-2; Sodium xylene sulfonate: 1300-72-7

Cumple con la norma estándar de Green Seal™ GS-37 para el medio ambiente y los limpiadores industriales. Limpador de propósito general de baja formación de espuma diseñado para uso en la mayoría de los pisos. Excelente para uso en restregadoras automáticas. Se enjuga fácilmente, dejando una superficie libre de película. El pH neutral no dañará los acabados del piso. Libre de Compuestos Orgánicos Volátiles. Libre de alquil fenol etoxilado (APE).

INSTRUCCIONES:

- Para limpieza manual:
1. Retire la suciedad floja con trapeador de polvo sin solución de producto.
 2. En una cubeta de trapeador, diluya el producto con agua fría de la llave según una proporción de 1:256 (1/2 oz/galón) hasta 1:64 (2 oz/galón) dependiendo del grado de suciedad.
 3. Trapee el piso utilizando el trapeador humedecido.
 4. Permita que el piso se seque completamente.
- Para restregado con restregadora automática:
1. Retire la suciedad floja con trapeador de polvo sin solución de producto.
 2. Coloque el producto en una restregadora automática según una proporción de dilución de 1:256 (1/2 oz/galón) hasta 1:64 (2 oz/galón) dependiendo del grado de suciedad.
 3. Seleccione la almohadilla de piso apropiada; la elección de almohadilla típica será roja o más clara.
 4. Realice una pasada sobre el piso con la restregadora automática, limpiando y recogiendo la solución usada en la misma pasada.
 5. Permita que el piso se seque completamente.
- Producto puro puede dañar algunas superficies. Sin fragancia agregada.



Producto puro puede causar irritación en los ojos. Producto puro puede causar irritación en la piel. Evite el contacto con los ojos y la piel. NO ingiera este producto. Se incluye información adicional sobre los efectos de la sobreexposición en la Hoja de Datos de Seguridad del Material que se puede conseguir por solicitud con su empleador.

Zep recomienda limitar la exposición a todos los productos químicos. Zep recomienda usar gafas de seguridad durante el uso y manipulación del producto. Para uso prolongado, se recomienda el uso de guantes de caucho, neopreno, nitrilo, u otros guantes resistentes. Quítese rápidamente la ropa contaminada y NO la utilice nuevamente hasta limpiarla minuciosamente. Después de la manipulación, lávese minuciosamente las manos con jabón y agua.

PRIMEROS AUXILIOS:

- OJOS:** Lávese inmediatamente los ojos con bastante agua durante al menos 15 minutos, levantando ocasionalmente los párpados superior e inferior. Obtenga atención médica inmediatamente.
- PIEL:** Lave la piel afectada, con abundante agua. Consulte con un médico si se desarrolla irritación.

INHALACIÓN: Si ocurren síntomas, traslade al aire fresco la persona expuesta. Si los síntomas persisten, obtenga atención médica.

INGESTIÓN: Si se ingiere este producto, NO induzca el vómito. Si la persona afectada está consciente, suministre bastante agua para beber. Llame inmediatamente a un centro toxicológico o un médico para solicitar recomendaciones de tratamiento.

INFORMACIÓN SOBRE DESECHO Y/O DERRAMES: Deshágase de cualquier producto en exceso o no utilizado de conformidad con las leyes federales, estatales y locales. Como con todos los procedimientos de limpieza y mantenimiento, el agua residual del proceso de limpieza o mantenimiento debe desviarse hacia un recipiente recolector, o donde sea permitido, hacia una alcantarilla sanitaria (consulte las normas-locales y estatales) y no permita que sea absorbida dentro del terreno o que ingrese a una alcantarilla de aguas lluvia. Si este producto es derramado o está contaminado y no puede utilizarse, creando la necesidad de desecho, absorba el producto mediante un material absorbente inerte, tal como el Zep-O-Zorb® o Zep-Zorbent, y deposite en un recipiente sellable. Enjuague bien el área con agua. Los recipientes vacíos del producto pueden reciclarse en áreas donde existan programas de reciclaje comunitarios.

ALMACENAMIENTO: Mantenga este producto alejado de los alimentos y productos alimenticios. Almacene en un recipiente cerrado herméticamente en una área seca a temperaturas entre 40°F (4°C) y 120°F (49°C).

MANTÉNGA FUERA DEL ALCANCE DE LOS NIÑOS SÓLO PARA USO INDUSTRIAL E INSTITUCIONAL NO ES PARA USO CASERO O REVENTA

This product is designed exclusively for industrial and institutional use by trained, professional maintenance personnel. Label directions and precautions must be followed exactly. Zep, Inc. will not be responsible for any injury, loss or damage, if product is used in any manner not in compliance with label directions, or, if precautions are not observed.

* This product meets the Green Seal™ environmental standard for industrial and institutional cleaners based on its reduced human and environmental toxicity and reduced volatile organic compound content.

Este producto cumple con la norma ambiental para limpiadores industriales e institucionales de Green Seal™ por su reducida toxicidad para los seres humanos y el medio ambiente, y su reducido contenido de compuestos orgánicos volátiles.



MADE IN USA by:
Zep Inc.
1310 Seaboard Ind. Blvd.
Atlanta, GA 30318
www.zep.com

V191




Zep Sales & Service
www.zep.com
1-877 BUY ZEP



PROD.#1914 • 110C

NEUTRAL Floor Cleaner

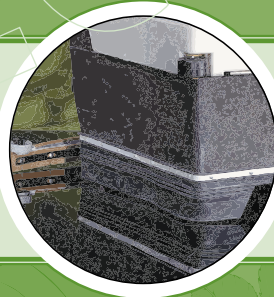

- Low Foam, General Purpose Cleaner
- Rinses Easily, Leaving a Film Free Surface
- Neutral pH Will not Harm Floor Finishes
- APE Free
- Fragrance - Mild (No Fragrance Added)

WARNING
CAUSES EYE IRRITATION
KEEP OUT OF REACH OF CHILDREN
ADVERTENCIA
CAUSA IRRITACIÓN DE LOS OJOS
MANTÉNGASE FUERA DEL ALCANCE DE NIÑOS



See back panel for additional precautionary statements
NET CONTENTS: 1 U.S. GALLON (3.78 L)