
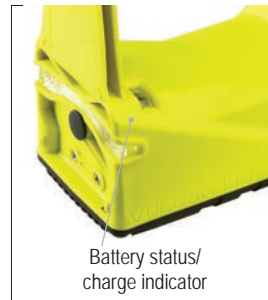


The lightest portable lantern of its kind, the Vulcan 180 is designed to burn brighter and run longer making it an essential firefighting and utility tool. It features a 180° tilting head that allows you to direct light where you need it. Three white LEDs produce extreme brightness and two ultra-bright blue taillight LEDs provide visibility in thick smoke.

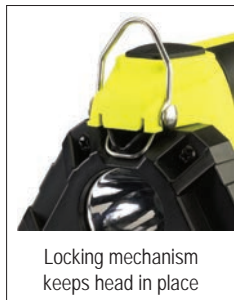

High and low modes:

- High for a bright, far-reaching beam: 1,200 lumens; 548m beam; runs 5.75 hours
- Low for a less intense beam and longer run time: 350 lumens; 296m beam; runs 16 hours

High-impact, super-tough nylon body; head constructed from high grade aluminum encased in super-tough nylon

Orange models include quick release strap  
Yellow models feature heavy duty strap; Configuration with quick release strap available

IPX7 waterproof to 1m submersion; 2m impact resistance tested

Class I Division 2 Groups A, B, C, D; Class II Division 2 Groups F, G; Class III; Temp. Class T4

Rack meets requirements of NFPA 1901-14.1.10.2 (2016) mounted in any position

7.43" (18.8cm); 2.47 lbs. (1.12kg)

Limited Lifetime Warranty  
Visit [streamlight.com](http://streamlight.com) for full warranty information

ORANGE QUICK RELEASE STRAP	YELLOW HEAVY DUTY STRAP	ITEM DESCRIPTION
44312	44302	Vulcan 180 Std Sys - 230V AC/12V DC
44313	44303	Vulcan 180 Std Sys - 240V (UK) AC/12V DC
44314	44304	Vulcan 180 Std Sys - 240V (AUS/NZ) AC/12V DC
44311	44301	Vulcan 180 Std Sys - 120V/100V AC/12V DC
YELLOW W/ QUICK RELEASE STRAP 44307		Vulcan 180 Std Sys - 120V/100V AC/12V DC
44315	44305	Vulcan 180 Vehicle Mount System - 12V DC
44310	44300	Vulcan 180 - Light Only