


Grommet, Brass
O.D. = 11/16"
I.D. = 9/32"

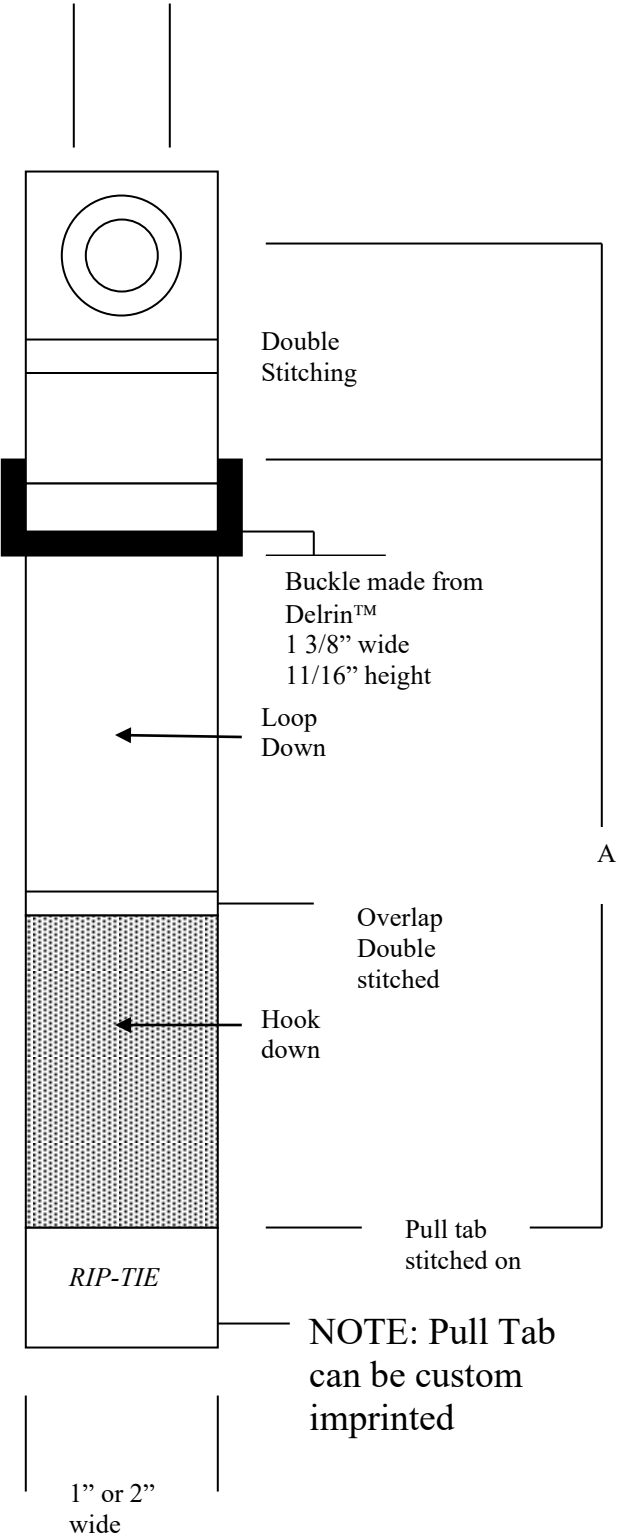

Drawing Not to Scale 2/22/07
Rip-Tie CinchStrap – EG
Rip-Tie, Inc.
PO Box 549
San Leandro, CA 94577
510 577- 0200 Phone
510-553-0160 Fax
Specifications subject to change.
Manufactured from hook and loop. 100% Nylon
2" wide has 2 grommets.
min tensile value HK88=125 lb
min tensile value LP 1000 = 95 lb.

A = Length Dimension
variable.
See attached sheet for
stock sizes. Custom sizes
also available.

NOTE: Pull Tab
can be custom
imprinted

CATALOG NUMBER	Max Bundle Diameter	COLOR	SIZE
N-07-G02- N-07-G10- N-07-G50-	1.50"	Black, Brown Red, Orange Yellow, Green Blue, Violet Grey, White or Specify <u>Rainbow</u> when ordering & receive all ten colors! 10-Pack includes one of each color 50-Pack includes five of each color	1" X 7" 1" X 7" 1" X 7"
N-10-G02- N-10-G10- N-10-G50-	2.50"		1" X 10" 1" X 10" 1" X 10"
N-16-G02- N-16-G10- N-16-G50-	4.25"		1" X 16" 1" X 16" 1" X 16"
N-22-G02- N-22-G10- N-22-G50-	6.25"		1" X 22" 1" X 22" 1" X 22"
N-28-G02- N-28-G10- N-28-G50-	8.25"		1" X 28" 1" X 28" 1" X 28"
N-34-G02- N-34-G10- N-34-G50-	10"		1" X 34" 1" X 34" 1" X 34"
N-46-G02- N-46-G10- N-46-G50-	14"		1" X 46" 1" X 46" 1" X 46"

O-16-G1P- O-16-G10- O-16-G50-	2.50"	Black, Brown Red, Orange Yellow, Green Blue, Violet Grey, White or Specify <u>Rainbow</u> when ordering & receive all ten colors! 10-Pack includes one of each color 50-Pack includes five of each color	2" X 16" 2" X 16" 2" X 16"
O-22-G1P- O-22-G10- O-22-G50-	4.50"		2" X 22" 2" X 22" 2" X 22"
O-28-G1P- O-28-G10- O-28-G50-	6.25"		2" X 28" 2" X 28" 2" X 28"
O-34-G1P- O-34-G10- O-34-G50-	8.25"		2" X 34" 2" X 34" 2" X 34"
O-46-G1P- O-46-G10- O-46-G50-	12"		2" X 46" 2" X 46" 2" X 46"
O-70-G1P- O-70-G10- O-70-G50-	19.75"		2" X 70" 2" X 70" 2" X 70"
O-94-G1P- O-94-G10- O-94-G50-	27.25"		2" X 94" 2" X 94" 2" X 94"

