

Ground Fault Devices

Commercial Tamper-Resistant and/or Weather-Resistant GFCI Receptacles



Features

- Patented shutter design for tamper-resistant protection
- Tamper-Resistant/Weather-Resistant Series meets NEC® requirements for TR (517-18c) and WR (406.9), UV and corrosion resistance for harsh and damp applications
- Weather-Resistant Only Series meets NEC® requirements for weather resistance (406.9), UV and corrosion resistance for harsh and damp applications
- Patented CIRCUITPRO® self-test technology
- Protects against line and load reversal, no power to the face or downstream if device is miswired



Tamper-Resistant Weather-Resistant

Rating	Color	Standard	Isolated Ground
NEMA 5-15, 15A 125V 	Almond	GFTWRST15AL	GFTWRST15ALIG
	Black	GFTWRST15BK	GFTWRST15BKIG
	Brown	GFTWRST15	GFTWRST15IG
	Gray	GFTWRST15GY	GFTWRST15GYIG
	Ivory	GFTWRST15I	GFTWRST15IIG
	Light Almond	GFTWRST15LA	GFTWRST15LAIG
	Orange	—	GFTWRST15ORIG
	Red	GFTWRST15R	GFTWRST15RIG
	White	GFTWRST15W	GFTWRST15WIG
	Almond	GFTWRST20AL	GFTWRST20ALIG
	Black	GFTWRST20BK	GFTWRST20BKIG
	Brown	GFTWRST20	GFTWRST20IG
NEMA 5-20, 20A 125V 	Gray	GFTWRST20GY	GFTWRST20GYIG
	Ivory	GFTWRST20I	GFTWRST20IIG
	Light Almond	GFTWRST20LA	GFTWRST20LAIG
	Orange	—	GFTWRST20ORIG
	Red	GFTWRST20R	GFTWRST20RIG
	White	GFTWRST20W	GFTWRST20WIG



Hospital Grade • Tamper-Resistant Weather-Resistant

Rating	Color	Standard	Isolated Ground
NEMA 5-15, 15A 125V 	Almond	GFST82ALTR	GFST82ALIG
	Black	GFST82BKTR	GFST82BKIG
	Brown	GFST82TR	GFST82IG
	Gray	GFST82GYTR	GFST82GYIG
	Ivory	GFST82ITR	GFST82IIG
	Light Almond	GFST82LATR	GFST82LAIG
	Orange	—	GFST82ORIG
	Red	GFST82RTR	GFST82RIG
	White	GFST82WTR	GFST82WIG
	Almond	GFST83ALTR	GFST83ALIG
	Black	GFST83BKTR	GFST83BKIG
	Brown	GFST83TR	GFST83IG
NEMA 5-20, 20A 125V 	Gray	GFST83GYTR	GFST83GYIG
	Ivory	GFST83ITR	GFST83IIG
	Light Almond	GFST83LATR	GFST83LAIG
	Orange	—	GFST83ORIG
	Red	GFST83RTR	GFST83RIG
	White	GFST83WTR	GFST83WIG




Weather-Resistant Only

Rating	Color	Standard
NEMA 5-15, 15A 125V 	Almond	GFWRST15AL
	Black	GFWRST15BK
	Brown	GFWRST15
	Gray	GFWRST15GY
	Ivory	GFWRST15I
	Light Almond	GFWRST15LA
	Red	GFWRST15R
	White	GFWRST15W
	Almond	GFWRST20AL
	Black	GFWRST20BK
	Brown	GFWRST20
	Gray	GFWRST20GY
NEMA 5-20, 20A 125V 	Ivory	GFWRST20I
	Light Almond	GFWRST20LA
	Red	GFWRST20R
	White	GFWRST20W

Product Dimensions Inches (mm)

	GFCI Receptacle
A	3.27" (83.1)
B	2.75" (69.8)
C	1.75" (44.5)
D	1.47" (37.4)
E	1.10" (27.9)

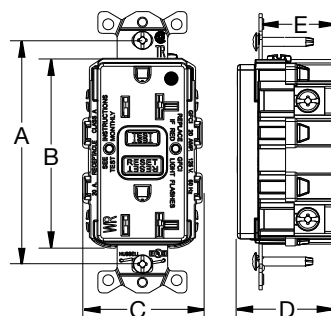

NEC® is a registered trademark of the National Fire Protection Association (NFPA).