

Commander® 8" Widespread Deck Faucet

FEATURES:

- Brass construction with corrosion resistant polished chrome finish
- 8" deep gooseneck rigid/swivel spout
- Vandal-resistant lever handle with color-coded indexes
- 1/4 turn ceramic cartridges to ensure drip-free performance
- Vandal-resistant 0.5 GPM (1.89 L/min) flow control
- Accommodates installations up to 3/4" thick
- 8" fixed centers
- 1/2" -14 NPSM inlets (supply lines not included)
- Drain assembly not included

AERATOR/FLOW RATE ADD-ONS:

- A-BOLF: 0.5 GPM (1.89 L/min) Boca Spray & 1.5 GPM (5.7 L/min) Laminar Flow Outlet Kit
- A-EA12: 1.2 GPM (4.54 L/min) Aerator Flow Control
- A-ELF: 1.2 GPM (4.54 L/min) Laminar Flow Aerator

HANDLE/HOSE ADD-ONS:

- A-CROSS: Cross Handle Kit
- A-LEVER: Lever Handle Kit

DRAIN ADD-ONS:

- S-3440: Strainer drain with chrome plated brass strainer plate
- S-3470: Chrome plated brass push pop-up drain

STANDARDS:

- ASME A112.18.1/CSA B125.1 certified
- NSF/ANSI 61 certified
- NSF/ANSI 372 certified

WARRANTY:

Visit www.speakman.com for full product warranty information

- 5 Year Limited Warranty (commercial)
- 5 Year Limited Warranty (residential)



Information continues on next page


1. All dimensions are in inches (millimeters) unless otherwise specified and are subject to change without notice.

Architect/Engineer Approval Space:

SPEAKMAN
400 ANCHOR MILL ROAD
NEW CASTLE, DE 19720

P: 800-537-2107
F: 800-977-2747
W: WWW.SPEAKMAN.COM
R: 01-MAY 2018

Commander® 8" Widespread Deck Faucet

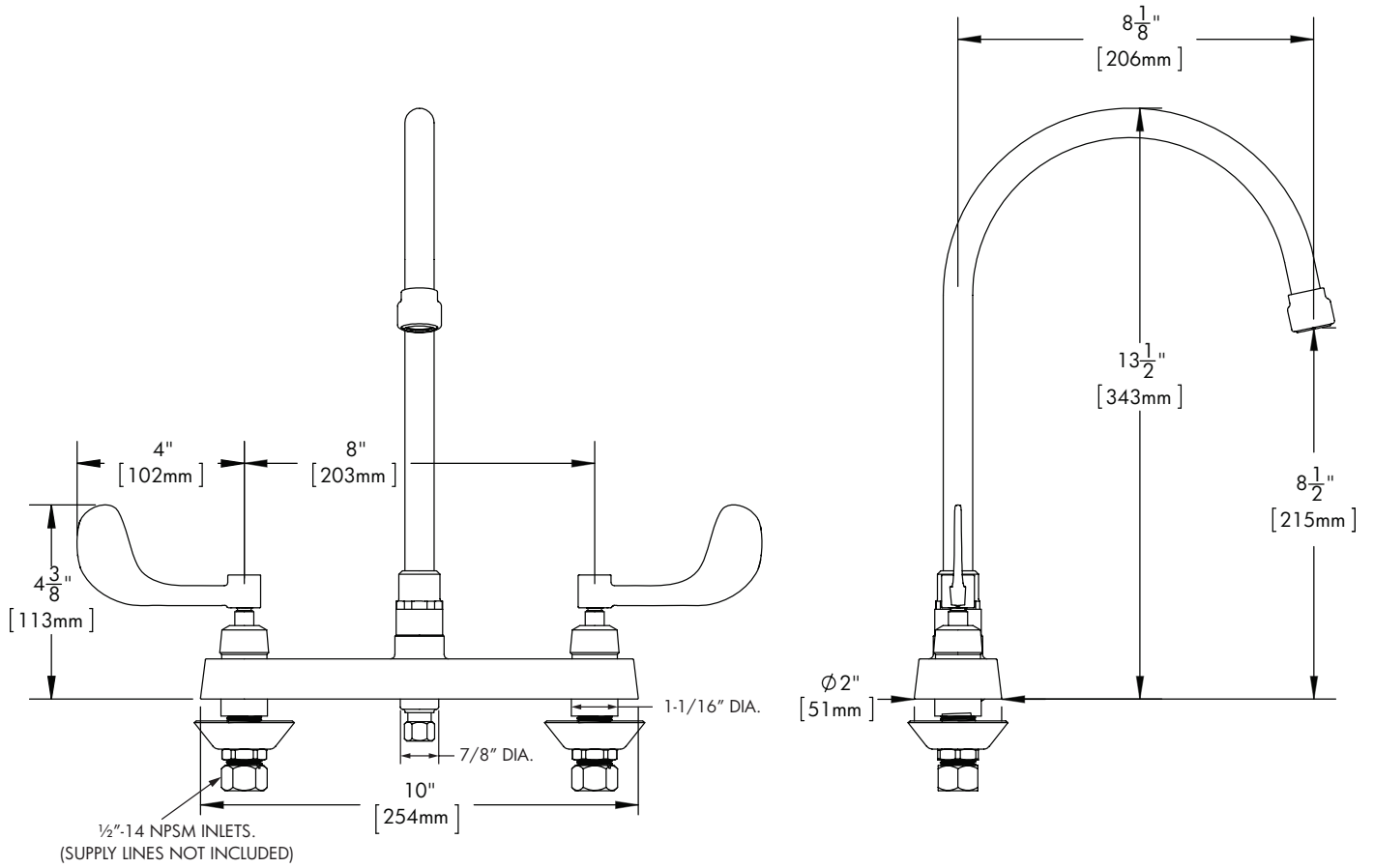

1. All dimensions are in inches (millimeters) unless otherwise specified and are subject to change without notice.

Architect/Engineer Approval Space:

SPEAKMAN
400 ANCHOR MILL ROAD
NEW CASTLE, DE 19720

P: 800-537-2107
F: 800-977-2747
W: WWW.SPEAKMAN.COM
R: 01-MAY 2018