

**DESCRIPTION**

- Solid brass construction
- Chrome, Brushed Chrome or Brushed Nickel finish
- 1/2" IPS connections
- Solid brass waterways

**OPERATION**

- Lever handle
- Temperature controlled through 110° arc of handle


**FLOW**

- Water usage is limited to these maximum flow rates as indicated by the corresponding product markings
  - 1.2 gpm max (4.5L/min) at 60 psi

**CARTRIDGE**


- Ceramic disc cartridge \*(with temperature limit stop)
- Nonmetallic/nonferrous and ceramic material

**STANDARDS**

- Third party certified to WaterSense,® ASME A112.18.1/CSA B125.1, and all applicable requirements referenced therein
- Certified to NSF 61/9 & 372
- Products marked with 1.2 gpm are compliant with California water efficiency regulations
- Complies with California Proposition 65 and with the Federal Safe Drinking Water Act
- **ADA**  for lever handle

**WARRANTY**


- Warranted for 5 years against material or manufacturing defects

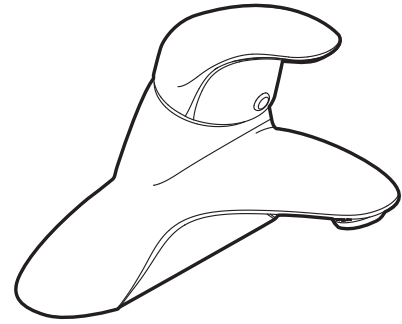

Single Handle Lavatory Faucet				
MODEL	FLOW (gpm)	DRAIN	FINISH	WATERSENSE CERTIFIED
8413F12	1.2	Without	Chrome	x
8414F12	1.2	With	Chrome	x
8414F12BN	1.2	With	Brushed Nickel	x



**NOTE:** This faucet is designed to be installed thru 3 holes, 1" min. dia.

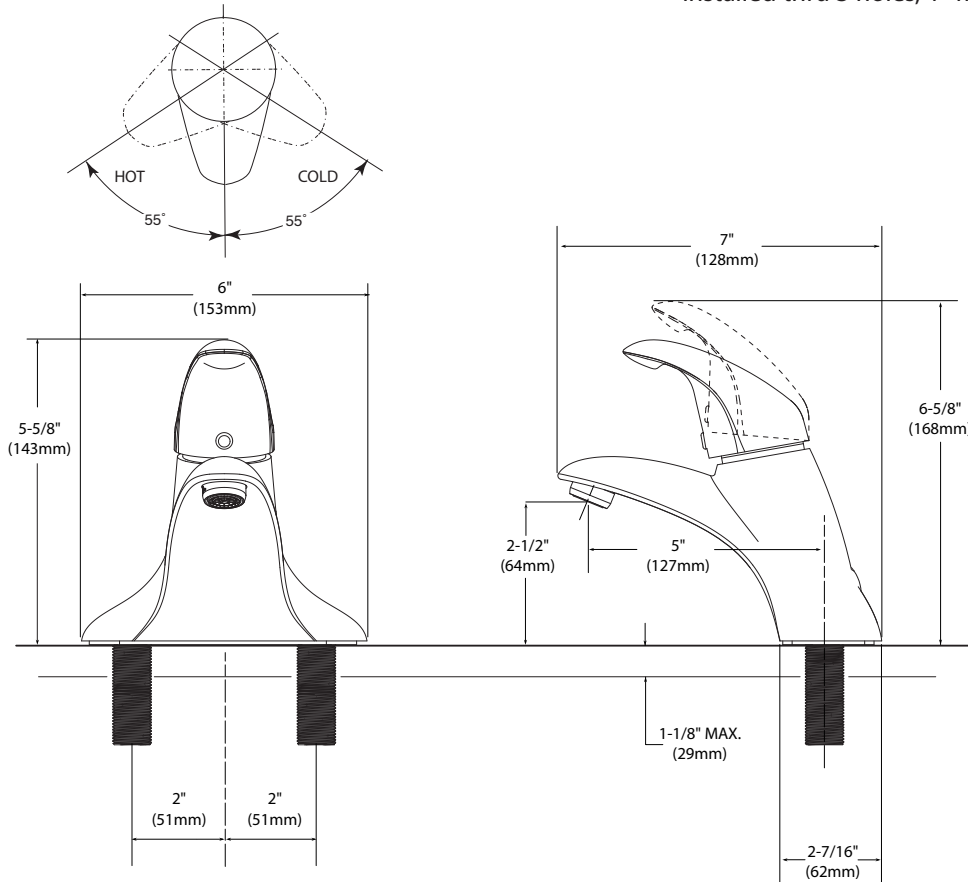

**CRITICAL DIMENSIONS**

(DO NOT SCALE)