




<p>fitted with</p> <p>connected load</p> <p>power consumption</p> <p>luminous flux</p> <p>luminous efficacy</p> <p>light distribution</p> <p>light color</p> <p>color rendering index (CRI)</p> <p>glare-free</p> <p>system of protection</p> <p>class of protection</p> <p>technology</p> <p>usage</p> <p>luminaire body</p> <p>lamp cover</p> <p>tubular sections</p> <p>weight (net)</p> <p>mains lead</p> <p>fastening</p> <p>special features</p>	<p>LED</p> <p>22-26 V; DC</p> <p>approx. 5 W</p> <p>approx. 460 lm</p> <p>approx. 92 lm/W</p> <p>direct, wide-angled beam</p> <p>neutral white, approx. 5000 K</p> <p>> 70</p> <p>screen</p> <p>IP 67</p> <p>III</p> <p>switchable</p> <p>pressure switch</p> <p>aluminium, painted, black</p> <p>glass screen</p> <p>flexible metal tube, black</p> <p>approx. 1.6 kg (3.5 lbs)</p> <p>approx. 3 m (9.8 ft); with free stranded wires</p> <p>screw-down flange</p> <p>Flood with 30° angle of radiation</p>
--	--



illuminance

distance: 50 cm
Em: 2969 lx
Emax: 5298 lx
Emin: 1085 lx

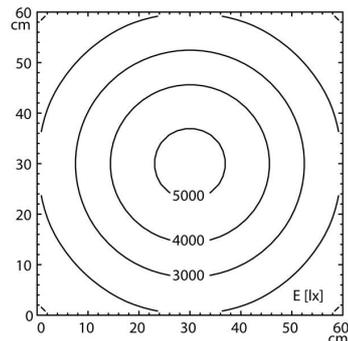

luminous intensity

