



fitted with

work equipment
connected load
power consumption
luminous flux
luminous efficacy
light distribution
light color
color rendering index (CRI)
glare-free
system of protection
class of protection
technology
usage
luminaire body
lamp cover
tubular sections
weight (net)
mains lead

LED

electronic plug-in transformer
 100-240 V; 50/60 Hz
 approx. 6 W
 approx. 490 lm
 approx. 82 lm/W
 direct, narrow-angled beam
 neutral white, approx. 5000 K
 > 70
 screen
 IP 67
 II with plug-in power supply; III without plug-in power supply
 switchable
 pressure switch
 aluminium, painted, black
 glass screen
 flexible metal tube, black
 approx. 1.7 kg (3.7 lbs)
 approx. 3 m (9.8 ft); mains plug
 US and foreign plugs included.

fastening
special features

screw-down flange
 Spot with a 10° angle of radiation



BS 1363 A




CEE 7/XVI



NEMA 1-15P

illuminance

distance: 50 cm
Em: 4520 lx
Emax: 26130 lx
Emin: 474 lx

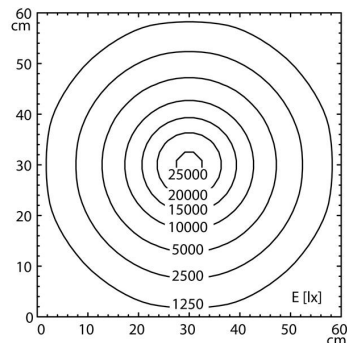

luminous intensity

