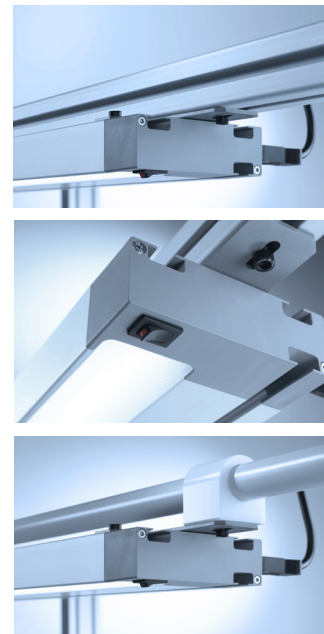

WLA
WORKPLACE-SYSTEM LUMINAIRES



WLA LED, Waldmann's task light for workbenches brings superb light quality (CRI>80) and color temperature (5000K) along with extreme energy-efficiency (50,000 hours of maintenance-free operation) to the factory workbench. The four lengths (17.7", 35.4", 47.2" and 59") make this strong, durable work light easy to match fixture to work space, no matter the size. In addition, the three longer versions are designed for easy thru-wire installation.



FEATURES

- LED overhead workstation light
- 50,000 hours of maintenance-free operation
- Thru-wire capability for daisy-chaining (except 17.7")
- Housing of anodized aluminum
- Premium LED materials and technology
- 5000K color temperature
- Built-in Wieland GS18/3 connector/socket
- T-Bracket set included
- ETL/cETL approved

SPECIFICATIONS

Voltage	120-277V; 50/60Hz
Lamping	LED
Color Temperature	5000K
Color Rendering Index (CRI)	>80
Luminaire Material	anodized aluminum
Lens Material	polycarbonate prismatic lens
Connection	built-in plug GST 18/3F REV
Protection Rating	IP20
Certification	ETL/cETL

ORDERING INFORMATION

Wattage	Length (A)	Lumens	Model	Part #
15W	17.7" (449mm)	1100	WLA 1100/850	113470000-00800170
37W	35.4" (899mm)	3000	WLA 3000/850/T	113475000-00704990
43W	47.2" (1199mm)	3700	WLA 3700/850/T	113476000-00704993
57W	59" (1499mm)	5000	WLA 5000/850/T	113477000-00704996

Accessories	Item	Part #
	T-Bracket set (Included)	408109019-00728797
	Thru-wire cable, 1-foot	330691010-00577361
	Thru-wire cable, 10-foot	330691020-00630438

Waldmann Lighting Company

9 Century Drive
 Wheeling, Illinois 60090
www.waldmannlighting.com

Telephone (847) 520 1060
 Fax (847) 520 1730
waldmann@waldmannlighting.com

Waldmann **W**

ENGINEERS OF LIGHT