



fitted with

work equipment
 connected load
 power consumption
 luminous flux
 luminous efficacy
 light color
 color rendering index (CRI)
 glare-free
 system of protection
 class of protection
 technology
 usage
 luminaire body
 lamp cover
 weight (net)
 mains supply

design
 fastening
 dimension
 special features

LED


electronic driver
 120-240V; 50/60Hz
 approx. 43 W
 approx. 3700 lm
 approx. 86 lm/W
 neutral white, approx. 5000 K
 > 80
 structured screen
 IP 20
 I
 switchable
 rocker switch
 aluminium/plastic, anodized, aluminium colored anodized
 structured screen
 approx. 4.1 kg (9.04 lbs)
 connection box, built-in plug
 GST 18i3F REV
 mounted version
 lamp bracket (accessory)
 A=1199 mm (47.20")
 through-wired




GST 18i3F REV

illuminance

distance: 100 cm
 Em: 1100 lx
 Emax: 1396 lx
 Emin: 741 lx

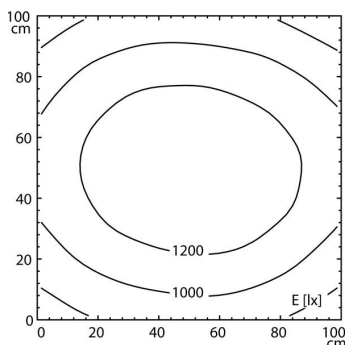

luminous intensity

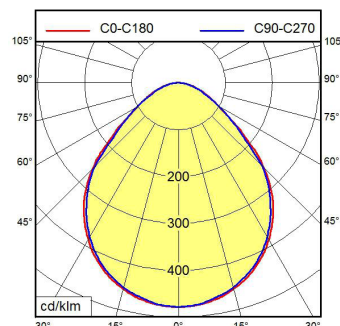

measurements in mm

