



**MCR
SAFETY**

6948

BlackJack

**Supported / Dipped gloves
Specification Sheet**

PRODUCT DESCRIPTION:

Black Jack® calls 'all in' and takes the hand. The protection you get from these bad boys is a notch above anything else you'll find in the industry. Awesome grip, protection, and performance. The 6948 is 18 inches in length and features rugged multi-dipped neoprene and a brushed interlock liner.

FEATURES:

- 18 inches in length
- Rugged Multi-Dipped Neoprene
- Smooth, fully coated
- Brushed Interlock Liner
- Gauntlet Cuff
- Component materials comply with all federal regulations for food contact

APPLICATIONS:

Agriculture, Construction, Farming, Janitorial , Oil and Gas Industry, Petrochemical industries, Sanitation, Medical



TECHNICAL DATA FOR: 6948

Series	BlackJack
Material Group	Supported
Product Type	Supported / Dipped gloves
Glove Size	Large
Material	Neoprene
Grade	Industrial Grade
Lining	Brushed Interlock
Thumb Style	Wing

Overall Length	18 in.
EN 388 : CE Score - Abrasion	3
EN 388 : CE Score - Cut	1
EN 388 : CE Score - Tear	2
EN 388 : CE Score - Puncture	1

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved




MCR
SAFETY

6948

BlackJack

Supported / Dipped gloves
Specification Sheet

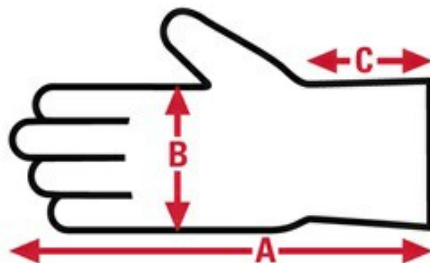

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
6948	Large	18.000	6.560	N/A	26.487 lb.	8.829

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved