



MCR SAFETY

9760 Predator

Supported / Dipped gloves Specification Sheet

PRODUCT DESCRIPTION:

The protection the Predator® gloves offer is unmatched in the market giving you the advantage over what you will face at work today. The 9760 Predator® features a premium nitrile palm coating on a soft jersey liner with Actifresh added to reduce odors and a safety cuff for additional protection.

FEATURES:

- Premium Nitrile Coating
- Soft Jersey Lining
- Safety Cuff for added safety
- Treated with Actifresh to reduce odor

APPLICATIONS:

Agriculture, Carpentry, Construction, Demolition, Farming, Forestry, Landscaping, Lumber industry, Material Handling



TECHNICAL DATA FOR: 9760

Series	Predator
Material Group	Supported
Product Type	Supported / Dipped gloves
Glove Size	Large
Material	Nitrile
Grade	Premium
Lining	Jersey
Thumb Style	Straight

Overall Length	11 in.
EN 388 : CE Score - Abrasion	4
EN 388 : CE Score - Cut	2
EN 388 : CE Score - Tear	3
EN 388 : CE Score - Puncture	2




MCR
SAFETY

9760

Predator

Supported / Dipped gloves
Specification Sheet

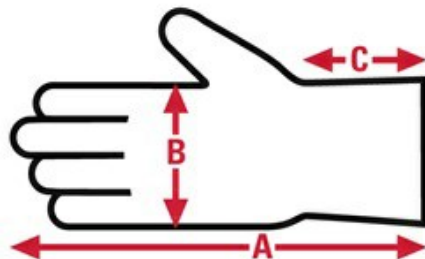

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
9760	Large	10.630	6.360	2.500	38.484 lb.	3.207
9760M	Medium	10.236	5.984	2.500	37.140 lb.	3.095
9760S	Small	0	0	N/A	32.400 lb.	2.700
9760XL	X - Large	11.023	6.496	2.500	42.012 lb.	3.501

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved