

The ORIGINAL Ground Protection Mats

Don't be fooled by knock-offs!



Ground Protection Matting


- Whether you need temporary access through harsh environments or need to get your equipment through a yard without damage, Checkers has you covered
- Mats for any size equipment, any application—with the highest load bearing capacity available on the market
- Durable, weather-resistant mats available in a full range of options

AlturnaMATS®

VersaMAT®

TrakMAT®

LibertyMAT®

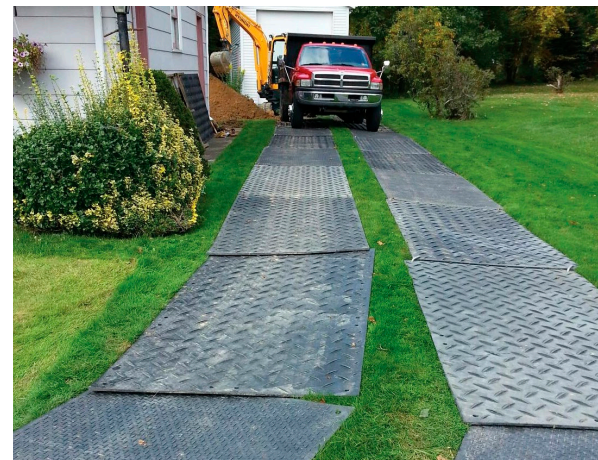

The Original Ground Protection Mats

Don't be fooled by knock-offs!

**AlturnaMATS® • VersaMAT®
TrakMAT® • LibertyMAT®**

For more than 30 years, Checkers has been the market leader for innovative ground protection. With the largest and most respected range of matting on the market, Checkers mats are durable and robust. Mats are offered in a variety of sizes, colors and traction surfaces ranging from rugged traction to low-profile pedestrian traction to smooth.



Why Use Ground Protection Mats?

Unmatched Turf Protection

Using ground protection mats helps to disperse heavy loads and minimize soil compaction, decreasing soil erosion and possible water contamination. The flexible construction follows the contours of the ground, delivering a highly effective solution on sloping or undulating ground conditions.



Superior Temporary Access

Ground protection mats get equipment safely through mud, sand, snow and swampland conditions. Access to and from remote sites and a stable work area are critical safety requirements in many industries, such as construction, landscaping, oil & gas, utilities, and civil engineering. Mats with pedestrian-friendly treads provide safe walking paths and temporary sidewalks.



Save Thousands Compared to Wood

Checkers™ HDPE Ground Protection Mats

Superior load capacity—up to 120 tons

Impressive traction and grip in any weather conditions

Flexible—conform to slopes and inclines

Weather resistant—no warping, splintering, or breaking

Reliable long term

VS



Plywood

No definitive load bearing rating

No traction; mud or ice buildup creates hazardous conditions for vehicles and personnel

Unsuitable for slopes or inclines


Absorbs water and liquids which accelerates rotting

Limited life span, resulting in a higher cost over time

Choose Your Matting Solution

Load Capacity

With load bearing up to 120 tons, mats provide secure solutions for a variety of equipment. Plus, they're lightweight and easily man-deployed.

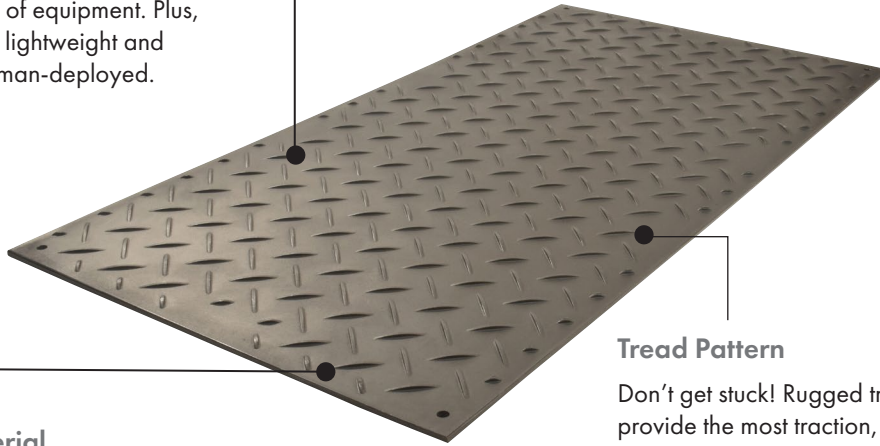

Material

HDPE (high-density polyethylene) mats are unaffected by weather, plus chemical and oil resistant. The plastic is flexible, conforming to uneven ground conditions to provide a secure surface.

Tread Pattern


Don't get stuck! Rugged treads provide the most traction, even in wet or icy conditions. Lower profile treads are ideal for pedestrians or walkways. Choose optional smooth sides to further protect hard surfaces.



Optional hand holes make handling easy.






Clear mats let the sun shine through to prevent browning of grass.

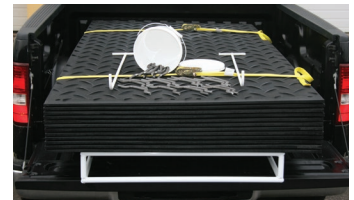

Available in convenient Mat-Pak bundles, complete with accessories.

A Complete Line of HDPE Mats

Rugged, durable HDPE mats with a complete range of options

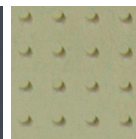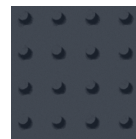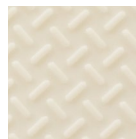

AlturnaMATS®

Aggressive diamond cleat tread ideal for heavy vehicle traffic

VersaMAT®

Low-profile flat oval tread ideal for pedestrian applications

TrakMAT®

Power cylinder tread improves grip, ideal for large vehicles

LibertyMAT®

Chevron traction tread is less aggressive to keep sensitive turf intact

Load bearing capacity*

120 tons

120 tons

90 tons

80 tons

Surface tread

Two standard options:
Diamond cleat (both sides) or
Diamond cleat / smooth

Two standard options:
Flat oval / diamond cleat or
Flat oval / smooth

Two standard options:
Power cylinder nub (both sides) or
Power cylinder nub / smooth

Chevron traction (both sides)

Available sizes

2 x 4 ft, 2 x 6 ft, 2 x 8 ft;
3 x 6 ft, 3 x 8 ft; 4 x 8 ft

2 x 8 ft, 3 x 8 ft, 4 x 8 ft

22 in x 8 ft, 3 x 8 ft, 44 in x 8 ft

4 x 8 ft

Available colors

Black or Clear

Black or Clear

Black or Cool Green

Black

Hand holes

Optional

Optional

Standard

Standard

Warranty

Limited lifetime

Limited lifetime

6 year limited warranty

1 year limited warranty

* Load bearing capacity is subject to ground conditions. Sizing is subject to a manufacturing variance of +/- 5%.


Matting Accessories

- Handi-Hook makes moving and retrieving mats easy, even in wet areas
- Connectors lock mats together to form a semi-permanent, yet portable continuous roadway, walkway or working platform



Mud-Traks® Ground Protection Mats

- Strength, durability and longevity to get through the harshest terrain
- Solid fiberglass grid structure channels tire load throughout the mat—rigid surface does not roll up, break or splinter
- Peak strength of 63,000 psi—very rigid, ideal for heavy multi-wheeled equipment with rubber tires (no steel tracks)

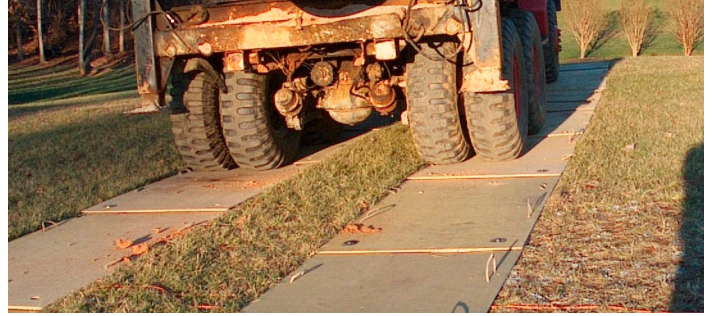

Outrigger Pads

- Safe, efficient support for heavy equipment with outrigger arms
- High load capacity fully supports vehicles and cranes without warping or splintering
- Ideal for construction vehicles, cranes, utility vehicles and more



GeoGrid Cellular Paving System

- Permanent ground reinforcement and stabilization system—grid design disperses rain and flood water to fight erosion
- Ideal for pedestrian areas, car parks, access routes, driveways and more
- Sections interlock for fast installation without tools

