



Saving Energy and Creating Healthy, Comfortable Environments



Air Curtain Fans for
ANSI/NSF37
Customer Entry maximum
mounting height is 7',
for unheated single-speed only

for outdoor use
single speed
unheated only

Superior Protection at a *Competitive Price*



**Multi-Purpose
air curtain**

MULTI-PURPOSE AIR CURTAIN MADE IN THE USA



*PLUNGER DOOR SWITCH STANDARD WITH NSF 37 UNITS



*THERMOSTAT, 24V DOOR SWITCH, TIME DELAY & TRANSFORMER STANDARD WITH HEATED UNITS

Standard Construction:

- 14" high x 15" deep
- White aluminum or stainless steel housing
- Wall & Top Mounting
- Simple to install, operate & maintain
- Optional: Filter (washable)

EPH Listed to NSF 37 Air Curtain:

Maximum recommended mounting height is 7'


- 3/4 hp single speed motor(s)
- Factory provided plunger door switch (to activate air curtain)

Electric Heated Air Curtain:

Maximum recommended mounting height is 10'

- 1/2 hp three speed motor(s)
- Factory installed fan speed/heat switch
- Patented venturi open helical element with point suspension:
 - Thermal overload protection
 - Galvanized steel frame

HOW A BERNER AIR CURTAIN WORKS

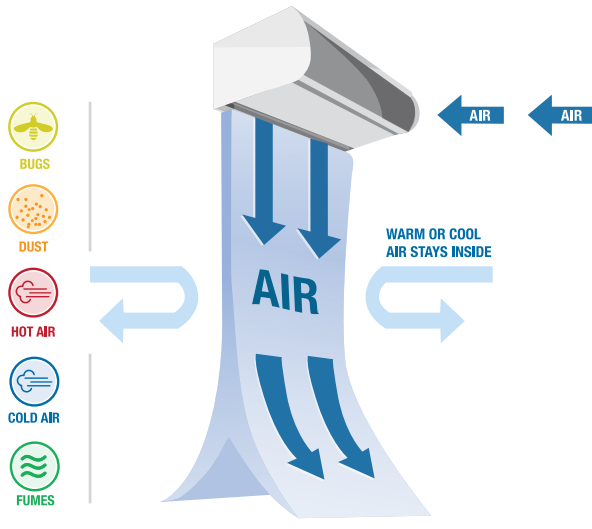

Benefits of Using a Berner Air Curtain:

SAVE ENERGY

An air curtain keeps outside air from entering and conditioned air from escaping when doors are opened.

CREATE COMFORT

Makes for a more comfortable environment inside for customers and employees.

PROMOTE INDOOR AIR QUALITY

Keeps insects, car fumes and dirt from entering the building.

Multipurpose, NSF 37 Unheated Air Curtain		
SKU	Mfr. Model	Description
6JGE3	SHD07-1036AC-P-G	36" 115/208-240V
6JGE4	SHD07-1042AC-P-G	42" 115/208-240V
6JGE5	SHD07-1048AC-P-G	48" 115/208-240V
6JGE6	SHD07-2072AC-P-G	72" 115/208-240V

Multipurpose, 3 Speed, Electric Heated Air Curtain		
SKU	Mfr. Model	Description
6JGE7	CHD10-1036EX-100-3X-G	36" 208/3
6JGF0	CHD10-1036EZ-100-3X-G	36" 460/3
6JGE8	CHD10-1048EX-100-3X-G	48" 208/3
6JGF1	CHD10-1048EZ-100-3X-G	48" 460/3
6JGE9	CHD10-2072EX-160-3X-G	72" 208/3
6JGF2	CHD10-2072EZ-160-3X-G	72" 460/3



Five years parts warranty - Unheated
Two years parts warranty - Heated

For more information contact your Grainger Representative or visit Grainger.com®.