



WORKSAFE

2206 LED

GRAINGER #48Z713 | 4D-CELL SAFETY ORANGE LANTERN


THE WORKSAFE LANTERN CAN BE USED IN HAZARDOUS ATMOSPHERES AND CARRIES A 150 HOUR RUNTIME

- Intrinsically Safe
- Waterproof, IP67 rating
- D' Cell Alkaline Batteries
- Switch Guard protects switch on impact
- Glove friendly handle



LIGHTWEIGHT, WATERPROOF, AND AFFORDABLE CLASS 1, DIVISION 1 LANTERN

FL1 STANDARDS

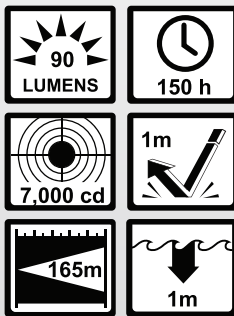

KBS MODEL: #08050

KBS ACCESSORY: #20414- KPR 113 Bulb

SPECIFICATIONS

POWER SOURCE: 4D-Cell alkaline batteries

LIGHT SOURCE: LED

LIGHT OUTPUT: 90 Lumens

PEAK BEAM INTENSITY: 7,000 candela

BEAM DISTANCE: 165 Meters

RUN TIME: 150 Hours (alkaline batteries)

MASTER PACK

WEIGHT: 14.66 oz without batteries

LENGTH: 8.2 in. WIDTH: 4.9 in. Height: 5.6 in.

COLORS: Safety Orange, Black Lens Rim

SAFETY RATINGS

UL protection Methods

UL 913 CSA C22.2

Intrinsically Safe Division 1 and 2

Class I, II, III Div 1 Groups A-G

Class I, II, III Div 2 Groups A-G

Operating Temp T5

*Safety ratings approvals based on Duracell MN1300 or Energizer E95 cells only



See it all.™

