


WORKSAFE LED FLASHLIGHT EARNS THE HIGHEST GLOBAL SAFETY APPROVALS AT THE MOST AFFORDABLE PRICE

- Class I, Division 1 Safety Approvals
- Intrinsically Safe
- Waterproof, IP67 rating
- Three-way switch : On-Momentary-Off
- 'Switch Guard' Prevents accidental lighting
- Impact resistant to one meter
- Easy grip, anti-roll barrel



IMPACT RESISTANT, WATERPROOF FLASHLIGHT RUNS FOR 200 HOURS

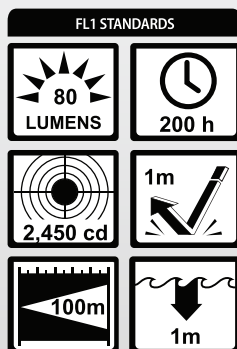

SPECIFICATIONS

POWER SOURCE: 2 D-Cell Batteries
LIGHT SOURCE: LED
LIGHT OUTPUT: 80 Lumens
PEAK BEAM INTENSITY: 2,450 candela
BEAM DISTANCE: 100 Meters
RUN TIME: 200 Hours
WEIGHT: 5 oz. without batteries
LENGTH: 8.1 in. **WIDTH:** 2.3 in.
COLORS: Safety Orange, Black Lens Rim

SAFETY RATINGS

UL protection Methods
 Intrinsically Safe Division 1 and 2
 Class I, II, III Div 1 Groups A-G
 Class I, II, III Div 2 Groups A-G
 Operating Temp T5

*Safety approvals based on Duracell MN1300 or Energizer E95 cells only

KOEHLER BRIGHTSTAR MODEL

#15460-2217 LED Orange Flashlight (Grainger #48Z714)

UPC-IC (12 Digit): 016731154608

KOEHLER BRIGHTSTAR ACCESSORIES

#23853 - 6 1/2" Red Snap In Wand

#23860 - 6 1/2" Yellow Snap In Wand



 **Marmon**
Holdings, Inc.
A Berkshire Hathaway Company

See it all.™

KBS