


**250 HOUR RUN TIME
WITH THE SAFETY RATINGS NEEDED
FOR HAZARDOUS ATMOSPHERES**

- Class I, Division 1 Safety Approvals
- Intrinsically Safe
- Waterproof, IP67 rating
- Three-way switch : On-Momentary-Off
- 'Switch Guard' Prevents accidental lighting
- Impact resistant to one meter
- Easy grip, anti-roll barrel



**IMPACT RESISTANT, WATERPROOF FLASHLIGHT
WITH A FACETED REFLECTOR FOR MORE LIGHT**

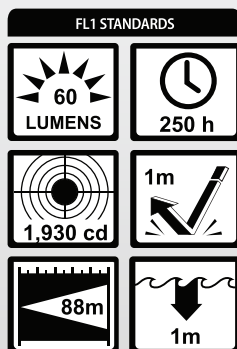

SPECIFICATIONS

POWER SOURCE: 3D-Cell Alkaline Batteries
LIGHT SOURCE: LED
LIGHT OUTPUT: 60 Lumens
PEAK BEAM INTENSITY: 1,930 candela
BEAM DISTANCE: 88 Meters
RUN TIME: 250 Hours
WEIGHT: 6 oz. without batteries
LENGTH: 10.2 in. **WIDTH:** 2.3 in.
COLORS: Safety Orange, Black Lens Rim

SAFETY RATINGS

UL protection Methods
 Intrinsically Safe Division 1 and 2
 Class I, II, III Div 1 Groups A-G
 Class I, II, III Div 2 Groups A-G
 Operating Temp T5

*Safety approvals based on Duracell MN1300 or Energizer E95 cells only

KOEHLER BRIGHTSTAR MODEL

#15720-2224 LED Orange Flashlight (Grainger #48Z715)

UPC-IC (12 Digit): 016731157203

KOEHLER BRIGHTSTAR ACCESSORIES

#23853 - 6 1/2" Red Snap In Wand

#23860 - 6 1/2" Yellow Snap In Wand



 Marmon
Holdings, Inc.
A Berkshire Hathaway Company

See it all.™

