

DEWALT®


20V^{MAX*}
LITHIUM ION™



THE ADVANTAGE

*Maximum initial battery voltage (measured without a workload) is 20 volts. Nominal voltage is 18.

3 POWER SOURCES**

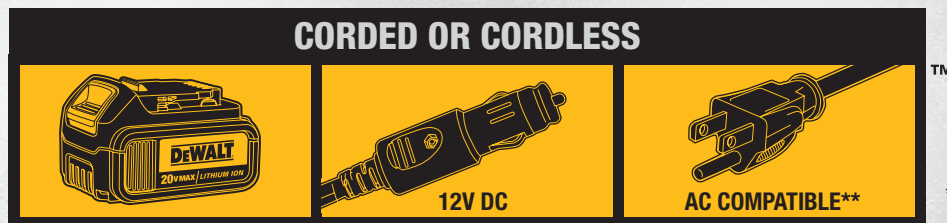

** AC power adapter sold separately

20V MAX* CORDED/CORDLESS AIR INFLATOR

DCC020IB



› Digital gauge with auto-shutoff for accuracy and ease of use.



› Use it on the jobsite or on the go for maximum versatility.

SPECIFICATIONS

High Pressure Operating Range	3-160 PSI
High Pressure SCFM (at 35 PSI)	0.5 [†]
High Volume SCFM	15.2
Tool Weight (Tool Only)	5.5 lbs

[†] Tested per ISO 1217

TOOL WARRANTY

3 YEAR	1 YEAR	90 DAY
LIMITED WARRANTY	FREE SERVICE	SATISFACTION GUARANTEE

RELATED PRODUCTS

DCC2560T1

DEWALT® FLEXVOLT® 60V MAX*
2.5 GALLON CORDLESS
AIR COMPRESSOR KIT



DCB230

20V MAX* 3 AH
COMPACT BATTERY



DWFP55126

HEAVY DUTY 165 PSI
PANCAKE COMPRESSOR



1-800-4-DEWALT www.DEWALT.com

Copyright ©2018 DEWALT. The following are examples of trademarks for one or more DEWALT power tools and accessories: the yellow and black color scheme; the "D"-shaped air intake grill; the array of pyramids on the handgrip; the kit box configuration; and the array of lozenge-shaped humps on the surface of the tool.