



Circline

FC8T9/DAYDLX/22W/8 12PK

T9 4-Pin Circular Fluorescent Lamps.

Warnings and Safety

· Lamp contains mercury. Manage in Accord with Disposal Laws. See: www.lamprecycle.org or 1-800-555-0050

Product data

General Information	
Base	G10Q [G10q]
Life to 50% Failures (Nom)	13000 h

Light Technical	
Color Code	54
Initial lumen (Nom)	910 lm
Color Designation	Cool Daylight
Lumen Maintenance 2000 h (Nom)	80 %
Lumen Maintenance 5000 h (Nom)	71 %
Correlated Color Temperature (Nom)	6200 K
Color Rendering Index (Nom)	79

Operating and Electrical	
Power (Rated) (Nom)	20.5 W
Lamp Current (Nom)	0.37 A
Voltage (Nom)	61 V

Controls and Dimming	
Dimmable	No


Mechanical and Housing	
Bulb Shape	C-T9 [C-T 29 mm (C-T9)]

Approval and Application	
Mercury (Hg) Content (Nom)	8.0 mg

Product Data	
Order product name	FC8T9/DAYDLX/22W/8 12PK
EAN/UPC - Product	046677392352
Order code	392357
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	928028405435
Net Weight (Piece)	0.110 kg

Circline

Dimensional drawing

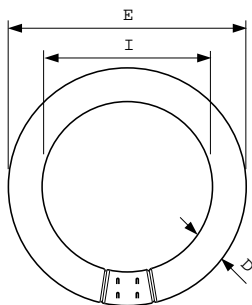

Product	D (max)	D (min)	E (min)	E (max)	I (min)	I (max)
FC8T9/ DAYDLX/22W/8 12PK	31.0 mm	26.2 mm	203.2 mm	215.9 mm	149.1 mm	155.7 mm

TL-E 22W/54 RS

