



Circline

FC12T9/COOL WHITE PLUS

T9 4-Pin Circular Fluorescent Lamps.

Warnings and Safety

· Lamp contains mercury. Manage in Accord with Disposal Laws. See: www.lamprecycle.org or 1-800-555-0050

Product data

General Information	
Base	G10Q [G10q]
Life to 50% Failures (Nom)	13000 h

Light Technical	
Color Code	33
Initial lumen (Nom)	1800 lm
Color Designation	Cool White (CW)
Lumen Maintenance 2000 h (Nom)	83 %
Lumen Maintenance 5000 h (Nom)	74 %
Correlated Color Temperature (Nom)	4100 K
Color Rendering Index (Nom)	62

Operating and Electrical	
Power (Rated) (Nom)	31 W
Lamp Current (Nom)	0.43 A
Voltage (Nom)	84 V

Controls and Dimming	
Dimmable	No


Mechanical and Housing	
Bulb Shape	C-T9 [C-T 29 mm (C-T9)]

Approval and Application	
Mercury (Hg) Content (Nom)	8.0 mg

Product Data	
Order product name	FC12T9/COOL WHITE PLUS
EAN/UPC - Product	046677391171
Order code	391177
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	928028603335
Net Weight (Piece)	0.180 kg

Circline

Dimensional drawing

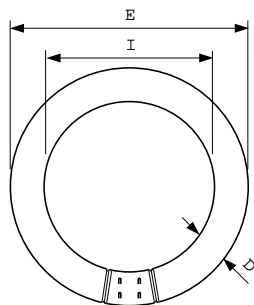

Product	D (max)	D (min)	E (min)	E (max)	I (min)	I (max)
FC12T9/COOL WHITE PLUS	31.0 mm	26.2 mm	292.1 mm	304.8 mm	239.5 mm	246.1 mm

TL-E 32W/33 RS

