



# Circline

## FC12T9/SOFTWHITE/32W/12 12PK

T9 4-Pin Circular Fluorescent Lamps.

### Warnings and Safety

· Lamp contains mercury. Manage in Accord with Disposal Laws. See: [www.lamprecycle.org](http://www.lamprecycle.org) or 1-800-555-0050


### Product data

General Information	
Base	G10Q [ G10q]
Life to 50% Failures (Nom)	13000 h
Light Technical	
Color Code	830 [ CCT of 3000K]
Initial lumen (Nom)	1900 lm
Color Designation	Warm White (WW)
Lumen Maintenance 2000 h (Nom)	84 %
Lumen Maintenance 5000 h (Nom)	77 %
Correlated Color Temperature (Nom)	3000 K
Color Rendering Index (Nom)	85
Operating and Electrical	
Power (Rated) (Nom)	31 W
Lamp Current (Nom)	0.43 A
Voltage (Nom)	84 V

Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Bulb Shape	C-T9 [ C-T 29 mm (C-T9)]
Product Data	
Order product name	FC12T9/SOFTWHITE/32W/12 12PK
EAN/UPC - Product	046677391225
Order code	391227
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	928028683035
Net Weight (Piece)	0.180 kg

# Circline

## Dimensional drawing

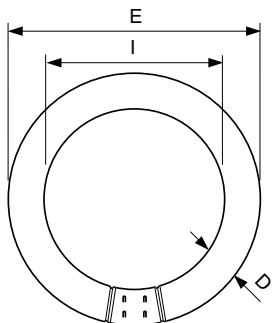

TL-E 32W/830 RS

Product	D (max)	D (min)	E (min)	E (max)	I (min)	I (max)
FC12T9/	31.0 mm	26.2 mm	292.1	304.8	239.5	246.1 mm
SOFTWHITE/32W/ 12 12PK			mm	mm	mm	

