



Circline

FC16T9/COOL WHITE PLUS

T9 4-Pin Circular Fluorescent Lamps.

Warnings and Safety

· Lamp contains mercury. Manage in Accord with Disposal Laws. See: www.lamprecycle.org or 1-800-555-0050

Product data

General Information	
Base	G10Q [G10q]
Life to 50% Failures (Nom)	13000 h

Light Technical	
Color Code	33
Initial lumen (Nom)	2500 lm
Color Designation	Cool White (CW)
Lumen Maintenance 2000 h (Nom)	87 %
Lumen Maintenance 5000 h (Nom)	78 %
Correlated Color Temperature (Nom)	4100 K
Color Rendering Index (Nom)	62

Operating and Electrical	
Power (Rated) (Nom)	39.5 W
Lamp Current (Nom)	0.42 A
Voltage (Nom)	109 V

Controls and Dimming	
Dimmable	No


Mechanical and Housing	
Bulb Shape	C-T9 [C-T 29 mm (C-T9)]

Approval and Application	
Mercury (Hg) Content (Nom)	8.0 mg

Product Data	
Order product name	FC16T9/COOL WHITE PLUS
EAN/UPC - Product	046677391188
Order code	391185
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	12
Material Nr. (12NC)	928028803335
Net Weight (Piece)	0.250 kg

Circline

Dimensional drawing

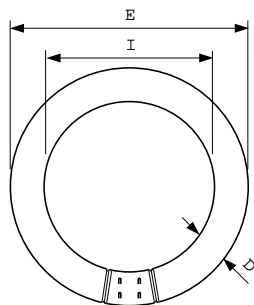

Product	D (max)	D (min)	E (min)	E (max)	I (min)	I (max)
FC16T9/COOL WHITE PLUS	30.9 mm	27.1 mm	393.7 mm	406.4 mm	341.0 mm	347.7 mm

TL-E 40W/33 RS

