



PL-L Long 4-Pin Base

PL-L 40W/830/4P/RS/IS

Philips Linear Compact Fluorescent Lamps offer designers, specifiers and end-users new levels of efficiencies and versatility in sizes, configurations and application possibilities. With so many elegant fixtures available to complement their small size, high light output and advanced technology, Philips Energy Advantage lamps are fast becoming the preferred choice when maximum efficiency and sleek design solutions are required.

Warnings and Safety


· Lamp contains mercury. Manage in Accord with Disposal Laws. See: www.lamprecycle.org or 1-800-555-0050

Product data

| General Information | | Lamp Current (Nom) | | 0.320 A |
|------------------------------------|---------------------|---------------------------------|-----------------------|---------|
| Base | 2G11 [2G11] | Voltage (Nom) | 126 V | |
| Life to 50% Failures (Nom) | 10000 h | Controls and Dimming | | |
| System Description | Rapid Start (RS) | Dimmable | Yes | |
| Light Technical | | Mechanical and Housing | | |
| Color Code | 830 [CCT of 3000K] | Cap-Base Information | 4P | |
| Initial lumen (Nom) | 3500 lm | Product Data | | |
| Color Designation | Warm White (WW) | Order product name | PL-L 40W/830/4P/RS/IS | |
| Lumen Maintenance 10000 h (Nom) | 91 % | EAN/UPC - Product | 046677111786 | |
| Lumen Maintenance 2000 h (Nom) | 94 % | Order code | 300426 | |
| Lumen Maintenance 5000 h (Nom) | 92 % | Numerator - Quantity Per Pack | 1 | |
| Correlated Color Temperature (Nom) | 3000 K | Numerator - Packs per outer box | 25 | |
| Luminous Efficacy (rated) (Nom) | 87 lm/W | Material Nr. (12NC) | 927908008329 | |
| Color Rendering Index (Nom) | 82 | Net Weight (Piece) | 140.000 g | |
| Operating and Electrical | | | | |
| Power (Rated) (Nom) | 36.3 W | | | |

PL-L Long 4-Pin Base


Dimensional drawing

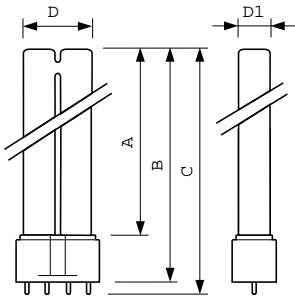

| Product | D (max) | D1 (max) | A (max) | B (max) | C (max) |
|-----------------------|---------|----------|----------|---------|----------|
| PL-L 40W/830/4P/RS/IS | 39.0 mm | 18.0 mm | 539.2 mm | 565 mm | 571.6 mm |

PL-L 40W/830/4P RS

 Photometric data



LDPB_PLLRS_830-Spectral power distribution B/W

LDPO_PLLRS_830-Spectral power distribution Colour

