



PL-L Long 4-Pin Base

PL-L 40W/841/4P/RS/IS

Philips Linear Compact Fluorescent Lamps offer designers, specifiers and end-users new levels of efficiencies and versatility in sizes, configurations and application possibilities. With so many elegant fixtures available to complement their small size, high light output and advanced technology, Philips Energy Advantage lamps are fast becoming the preferred choice when maximum efficiency and sleek design solutions are required.

Warnings and Safety


· Lamp contains mercury. Manage in Accord with Disposal Laws. See: www.lamprecycle.org or 1-800-555-0050

Product data

General Information		Lamp Current (Nom)		0.320 A
Base	2G11 [2G11]	Voltage (Nom)	126 V	
Life to 50% Failures (Nom)	10000 h	Controls and Dimming		
System Description	Rapid Start (RS)	Dimmable	Yes	
Light Technical		Mechanical and Housing		
Color Code	841 [CCT of 4100K]	Cap-Base Information	4P	
Initial lumen (Nom)	3500 lm	Product Data		
Color Designation	Cool White (CW)	Order product name	PL-L 40W/841/4P/RS/IS	
Lumen Maintenance 10000 h (Nom)	91 %	EAN/UPC - Product	046677111809	
Lumen Maintenance 2000 h (Nom)	94 %	Order code	300442	
Lumen Maintenance 5000 h (Nom)	92 %	Numerator - Quantity Per Pack	1	
Correlated Color Temperature (Nom)	4100 K	Numerator - Packs per outer box	25	
Luminous Efficacy (rated) (Nom)	87 lm/W	Material Nr. (12NC)	927908008429	
Color Rendering Index (Nom)	82	Net Weight (Piece)	140.000 g	
Operating and Electrical		ILCOS Code	FSD-40/40/1B-L/P-2G11	
Power (Rated) (Nom)	36.3 W			

PL-L Long 4-Pin Base


Dimensional drawing

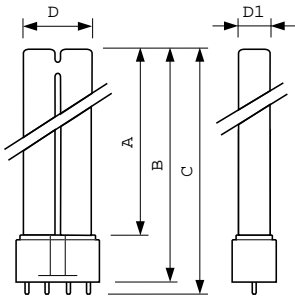

Product	D (max)	D1 (max)	A (max)	B (max)	C (max)
PL-L 40W/841/4P/RS/IS	39 mm	18 mm	540 mm	565 mm	571.6 mm

PL-L 40W/840/4P RS

 Photometric data



LDPB_PLLRS_840-Spectral power distribution B/W

LDPO_PLLRS_840-Spectral power distribution Colour

