



MCR
SAFETY

9761 Predator

Supported / Dipped gloves Specification Sheet

PRODUCT DESCRIPTION:

The protection the Predator® gloves offer is unmatched in the market giving you the advantage over what you will face at work today. The 9761 Predator® features fully coated premium nitrile on a soft jersey liner. It also features a safety cuff and is treated with Actifresh to reduce odors.

FEATURES:

- Fully Coated Premium Nitrile Coating
- Soft Jersey Lining
- Safety Cuff for additional protection
- Treated with Actifresh to reduce odors

APPLICATIONS:

Agriculture, Carpentry, Construction, Farming, Forestry, Material Handling, Metal fabrication



TECHNICAL DATA FOR: 9761

Series	Predator	Overall Length	11 in.
Material Group	Supported	EN 388 : CE Score - Abrasion	4
Product Type	Supported / Dipped gloves	EN 388 : CE Score - Cut	2
Glove Size	Large	EN 388 : CE Score - Tear	2
Material	Nitrile	EN 388 : CE Score - Puncture	1
Grade	Premium		
Lining	Jersey		
Thumb Style	Straight		

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com


©2018 MCR Safety - All Rights Reserved



MCR
SAFETY

9761 Predator

Supported / Dipped gloves
Specification Sheet

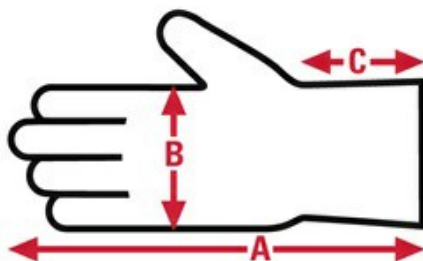

Item No:	Size:	A:	B:	C:	Case Weight	UOM Weight
9761	Large	10.630	6.360	2.500	45.360 lb.	3.780

MCR Safety - 1255 Schilling Blvd. W. - Collierville, TN 38017 - USA

Phone: 901-795-5810 - Toll Free: 800-955-6887 - Fax: 800-999-3908 - Web: www.mcrcsafety.com

©2018 MCR Safety - All Rights Reserved