

Hospital Grade ●, HBL® Extra Heavy Duty, Isolated Ground Receptacles




15A 125V
NEMA 5-15R
UL CSA
0.5 HP



20A 125V
NEMA 5-20R
UL CSA
1 HP

| Description | Color | Catalog Number | |
|--|--------|----------------|-----------------|
| Flush, thermoplastic polyester face, duplex, back and side wired, multiple drive screws. | Orange | IG8200 | IG8300 |
| | Red | IG8200R | IG8300R |
| Style Line® decorator. | Orange | — | IG2182 |
| | Ivory | — | IG2182I |
| | White | — | IG2182WA |
| Flush, thermoplastic polyester face, single. | Orange | IG8210 | IG8310 |

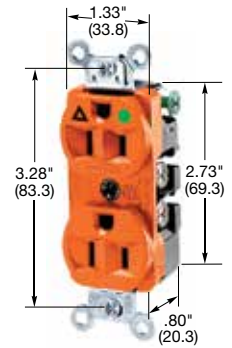

IG8200

15A and 20A, 125V HBL® Extra Heavy Duty, Specification Grade, Isolated Ground Receptacles




15A 125V
NEMA 5-15R
UL CSA
0.5 HP




20A 125V
NEMA 5-20R
UL CSA
1 HP


| Description | Color | Catalog Number | |
|--|--------------|-------------------|-------------------|
| Flush, nylon face, duplex, back and side wired, multiple drive screws. | Orange | IG5262 | IG5362 |
| | Gray | IG5262GY | IG5362GY |
| | Ivory | IG5262I | IG5362I |
| | Red | IG5262R | IG5362R |
| | White | — | IG5362W |
| Weather Resistant, duplex, isolated ground. | Orange | IG5262WR | IG5362WR |
| | Gray | IG5262GYWR | IG5362GYWR |
| | Ivory | IG5262IWR | IG5362IWR |
| | Red | IG5262RWR | IG5362RWR |
| | White | — | IG5362WWR |
| Finder groove, nylon face, duplex, back and side wired. | Orange | CR5252IG | CR5352IG |
| | Black | CR5252IGBK | CR5352IGBK |
| | Blue | — | CR5352IGBL |
| | Gray | CR5252IGGY | CR5352IGGY |
| | Ivory | CR5252IGI | CR5352IGI |
| | Office White | CR5252IGOW | CR5352IGOW |
| | White | CR5252IGW | CR5352IGW |
| Style Line® decorator, flush, nylon face, back and side wired. | Orange | IG2152 | IG2162 |
| | Gray | — | IG2162GY |
| 4-PLEX® receptacle. | Orange | IG415 | IG420* |
| Flush, nylon face, single, back and side wired. | Orange | IG5261 | IG5361 |
| | Orange | IG5261WR | IG5361WR |

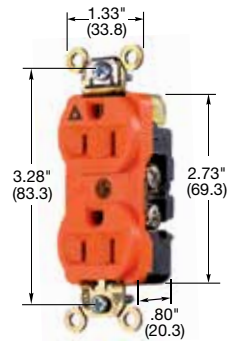

IG5262

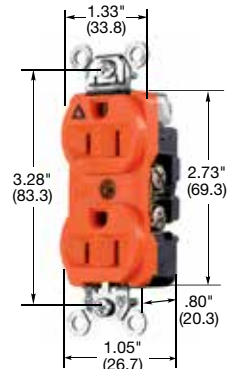

CR5252IG

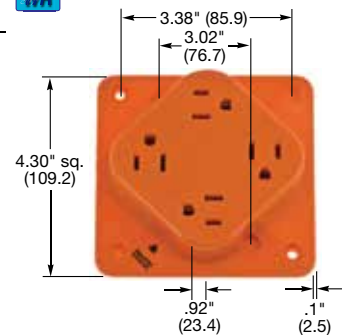

IG415

Note: *Not Fed. Spec. Listed.
See page Tech-10 for Weather Resistant description.
See page A-47 and A-48 for accessories.
See page A-28 for 4-PLEX accessories.

Dimensions in Inches (mm)