


# 8501XC4

NEMA Control Relay, Type X, master contact cartridge, 10A resistive at 600 VAC, 1 NO or 1 NC contact

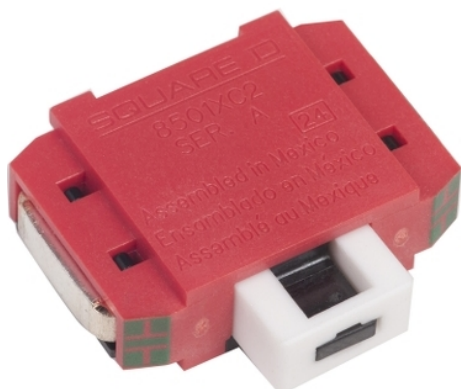

## Main

Range of Product	8501X
Relay Type	Control relay
Product or Component Type	Master contact cartridge

## Complementary

Rated breaking capacity	6 A 120 V AC inductive control circuit UL 508 3 A 240 V AC inductive control circuit UL 508 1.5 A 480 V AC inductive control circuit UL 508 1.2 A 600 V AC inductive control circuit UL 508 10 A <= 600 V AC resistive control circuit UL 508 1.1 A 125 V DC inductive control circuit UL 508 0.55 A 250 V DC inductive control circuit UL 508 0.2 A 301...600 V DC inductive control circuit UL 508 4 A 125 V DC resistive control circuit UL 508 0.8 A 250 V DC resistive control circuit UL 508
[Icm] rated short-circuit making capacity	60 A 120 V AC inductive control circuit UL 508 30 A 240 V AC inductive control circuit UL 508 15 A 480 V AC inductive control circuit UL 508 12 A 600 V AC inductive control circuit UL 508 10 A <= 600 V AC resistive control circuit UL 508 1.1 A 125 V DC inductive control circuit UL 508 0.55 A 250 V DC inductive control circuit UL 508 0.2 A 301...600 V DC inductive control circuit UL 508 4 A 125 V DC inductive control circuit UL 508 0.8 A 250 V DC resistive control circuit UL 508
Contacts Configuration	1 NO 1 master contact cartridge

## Environment

Product Certifications	UL recognized E78403 CCN NKCR2 CE CSA LR60905 class 3211 02
------------------------	---

## Ordering and shipping details

Category	21159 - 8501 X ACCESSORIES
Discount Schedule	CP2
GTIN	785901537137
Nbr. of units in pkg.	1
Package weight(Lbs)	0.02 lb(US) (0.01 kg)
Returnability	Yes
Country of origin	MX

## Packing Units

Package 1 Height	8.89 in (22.581 cm)
Package 1 width	3.50 in (8.890 cm)
Package 1 Length	22.58 in (57.355 cm)

## Offer Sustainability

California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>
EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS Declaration</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	<a href="#">End Of Life Information</a>

## Contractual warranty

Warranty	18 months
----------	-----------